
 


# Universal Compatibility Docking Stations

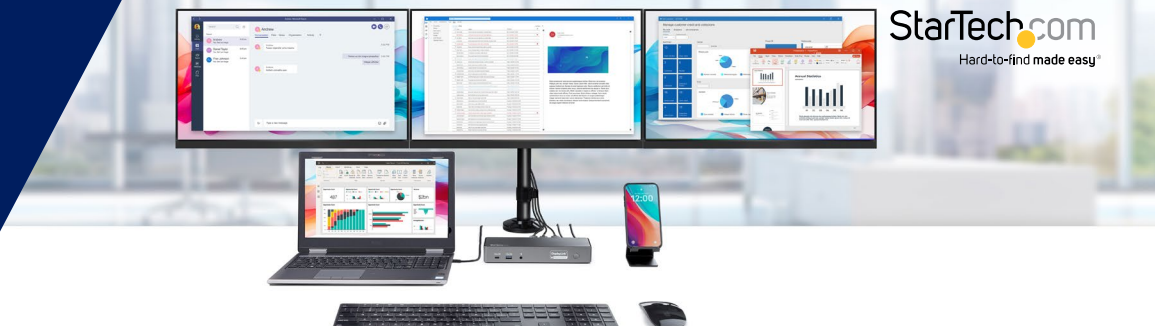

## Why StarTech.com



Included Power Supply is rated to provided full power to all ports and laptop charging without sharing or throttling.



Lock Slots (k-slots) for device security preventing dock and other lockable attached workstation equipment from being removed.



StarTech.com Connectivity Tools. MAC Address Pass-through, WiFi Auto Switching, Windows Layout, USB Event Monitoring (Windows only).

## Guaranteed Compatibility

- Universal Compatibility with Windows Laptops, MacBook Laptops, and Chromebooks.
- Enable Multiple Displays on MacBook Air / Pro with Apple M Series Chips.



DK30CH2DEP



116N-USBC-DOCK



DK30C2DPEP



DK30CHHPD



DKM30CHDPD

NEW



129N-USBC-KVM-DOCK



DK31C4DPPD

	DK30CH2DEP	116N-USBC-DOCK	DK30C2DPEP	DK30CHHPD	DKM30CHDPD	Specialty Docks	
Connection to Laptop (Host)	USB-C	USB-C	USB-C USB-A	USB-C	USB-C	USB-C (KVM Dock Supports Dual Hosts)	USB-C
# of Monitors Supported / Max Resolution	2x 4K 60Hz (DP) 1x 4K 30Hz (HDMI)	4K 60Hz	4K 60Hz	1080p	4K 30Hz	4K 60Hz	4K 60Hz
	Enable Multiple Displays on MacBook Air / Apple M Series MacBook Laptops					-	Enable Multiple Displays on MacBook Air / Apple M Series MacBook Laptops
DisplayLink Certified	✓	✓	✓	✓	-	✓	✓
Video Ports	1x HDMI/2x DP	3x HDMI/2x DP	2x DP/2x HDMI	2x HDMI	1x DP or 1x VGA	2x DP	4x HDMI, 4x DP
OS Compatibility	Windows, macOS, ChromeOS & Ubuntu	Windows, macOS, ChromeOS & Ubuntu	Windows, macOS, & ChromeOS	Windows, macOS, ChromeOS, Ubuntu	Windows, macOS, ChromeOS, iPadOS	Works with mixed OS (combine Windows, macOS or Chrome OS)	Windows, macOS, ChromeOS & Ubuntu
Power Delivery	100W	100W	100W	65W	65W	Dual Laptop Charging: 90W to active host and 45W to standby host	100W
# of USB-A Ports / Max Data Transfer Rate	4x USB-A 5 Gbps	1x USB-A 10 Gbps 2x USB-A 5 Gbps	1x USB-A 10 Gbps 2x USB-A 5 Gbps	3x USB-A 5 Gbps	3x USB-A 5 Gbps	2x USB-A 10 Gbps 2x USB 2.0	3x USB-A 5 Gbps
# of USB-C Ports / Max Data Transfer Rate	1x USB-C 5 Gbps	1x USB-C 10 Gbps	1x USB-C 10 Gbps	1x USB-C 5 Gbps	1x USB-C 5 Gbps	1x USB-C 10 Gbps	1x USB-C 10 Gbps
USB Port(s) Charging Capable	1x USB-A 7.5W	1x USB-C 7.5W 1x USB-A 7.5W	1x USB-C 15W 1x USB-A 7.5W	1x USB-C 7.5W 1x USB-A 7.5W	1x USB-C 15W 1x USB-A 7.5W	-	1x USB-C 15W 1x USB-A 7.5W
Total # of USB Ports	5	4	4	4	4	5	4

# High Performance Docking Stations



## Why StarTech.com



Included Power Supply is rated to provided full power to all ports and laptop charging without sharing or throttling.



Lock Slots (k-slots) for device security preventing dock and other lockable attached workstation equipment from being removed.



StarTech.com Connectivity Tools. MAC Address Pass-through, WiFi Auto Switching, Windows Layout, USB Event Monitoring (Windows only).

## High Performance Docks

- Utilizes GPU Performance
- Ideal for demanding and graphic intensive applications without the need for software or compressing video.
- Driverless ensures easy deployment.

NEW



132N-TB4USB4DOCK



TB4CDOCK



TB3CDK2DH



DK31C2DHSFP



MST30C2HHPD



DK31C3MNCR

Host Connection	Thunderbolt 4	Thunderbolt 4	Thunderbolt 3	USB-C	USB-C	USB-C
# of Monitors Supported / Max Resolution	 <b>Up to Quad Monitors (Windows)</b> Up to 4K 60Hz (Quad) Up to 5K 60Hz (Dual) Up to 8K 60Hz (Single, HDMI Only)	 <b>5K 60Hz</b> Up to 5K 60Hz (Dual) Up to 8K 30Hz	 <b>4K 60Hz</b>	 <b>4K 60Hz</b>	 <b>4K 30Hz</b>	 <b>Dual 4K 60Hz</b> <b>Triple 4K 30Hz</b>
Dual Display on MacBook Pro with Apple M Series Pro and Max Chips						
Video Ports	2x HDMI, 2x DP	3x TB4	2x HDMI, 2x DP	1X HDMI, 2X DP	2x HDMI, 2x HDMI/DVI Adapters	2x HDMI, 2x DP 1x USB-C DP Alt Mode
Driverless	✓	✓	✓	✓	✓	✓
OS Compatibility	Windows, macOS	Windows, macOS, ChromeOS	Windows, macOS, ChromeOS, Ubuntu	Windows, ChromeOS	Windows, ChromeOS	ChromeOS
Power Delivery	98W	98W	96W	100W	60W	60W
# of USB-A Ports / Max Data Transfer Rate	3x USB-A <sup>10 Gbps</sup> 2x USB-A <sup>5 Gbps</sup> 1x USB 2.0	3x USB-A <sup>10 Gbps</sup> 1x USB 2.0	1x USB-A <sup>10 Gbps</sup> 2x USB-A <sup>5 Gbps</sup>	2x USB-A <sup>5 Gbps</sup> 2x USB 2.0	4x USB-A <sup>5 Gbps</sup>	3x USB-A <sup>10 Gbps</sup> 2x USB 2.0
# of USB-C Ports / Max Data Transfer Rate	1x USB-C <sup>10 Gbps</sup>	3x TB4	2x USB-C <sup>10 Gbps</sup>	2x USB-C <sup>10 Gbps</sup>	1x USB-C <sup>5 Gbps</sup>	1x USB-C <sup>10 Gbps</sup> 1x USB-C <sup>10 Gbps</sup> with DP Alt Mode video
USB Port(s) Charging Capable	1x USB-C 15W 1x USB-A 7.5W	3x TB4/USB4 15W 1x USB-A 7.5W	1x USB-C 15W 1x USB-A 7.5W	2x USB-C 15W	1x USB-A 7.5W	1x USB-A 7.5W 2x USB-C 7.5W
Hardware Platform Compatibility	Apple M1 / M2 / M3 & Intel MacBook Thunderbolt 3 & TB4  Intel Thunderbolt 4 with Windows	Apple M Series & Intel MacBook Thunderbolt 3 & 4  Intel Thunderbolt 4 with Windows & Chromebooks	Apple M Series & Intel MacBook Thunderbolt 3 & 4  Intel Windows, Chromebooks	Intel Windows AMD Chromebooks with USB-C DP Alt Mode	Intel Windows AMD Chromebooks with USB-C DP Alt Mode	Chromebooks with USB-C DP Alt Mode