


Universal Compatibility Docking Stations

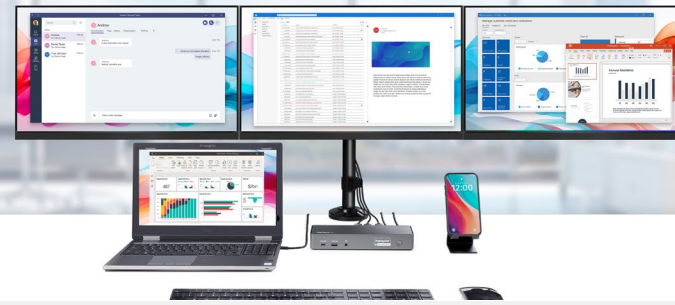

Why StarTech.com



Included Power Supply is rated to provide full power to all ports and laptop charging without sharing or throttling.



Lock Slots (k-slots) for device security preventing dock and other lockable attached workstation equipment from being removed.



StarTech.com Connectivity Tools. MAC Address Pass-through, WiFi Auto Switching, Windows Layout, USB Event Monitoring (Windows only).

Guaranteed Compatibility

- Universal Compatibility with Windows Laptops, MacBook Laptops, and Chromebooks.
- Enable Multiple Displays on MacBook Air / Pro with Apple M Series Chips.



DK30CH2DEPUE



116U-USBC-DOCK



DK30C2DPEPUE



DK30CHHPDUK



DKM30CHDPPDUE

NEW



129UE-USBC-KVM-DOCK



DK31C4DPPDUE

	DK30CH2DEPUE	116U-USBC-DOCK	DK30C2DPEPUE	DK30CHHPDUK	DKM30CHDPPDUE	Specialty Docks	
Connection to Laptop (Host)	USB-C	USB-C	USB-C USB-A	USB-C	USB-C	USB-C (KVM Dock Supports Dual Hosts)	USB-C
# of Monitors Supported / Max Resolution	2x 4K 60Hz (DP) 1x 4K 30Hz (HDMI)	4K 60Hz	4K 60Hz	1080p	4K 30Hz	4K 60Hz	4K 60Hz
DisplayLink Certified	✓	✓	✓	✓	–	✓	✓
Video Ports	1x HDMI/2x DP	3x HDMI/2x DP	2x DP/2x HDMI	2x HDMI	1x DP or 1x VGA	2x DP	4x HDMI, 4x DP
OS Compatibility	Windows, macOS, ChromeOS & Ubuntu	Windows, macOS, ChromeOS & Ubuntu	Windows, macOS, ChromeOS & Ubuntu	Windows, macOS, ChromeOS, Ubuntu	Windows, macOS, ChromeOS, iPadOS	Works with mixed OS (combine Windows, macOS or Chrome OS)	Windows, macOS, ChromeOS & Ubuntu
Power Delivery	100W	100W	100W	65W	65W	Dual Laptop Charging: 90W to active host and 45W to standby host	100W
# of USB-A Ports / Max Data Transfer Rate	4x USB-A 5 Gbps	1x USB-A 10 Gbps 2x USB-A 5 Gbps	1x USB-A 10 Gbps 2x USB-A 5 Gbps	3x USB-A 5 Gbps	3x USB-A 5 Gbps	2x USB-A 10 Gbps 2x USB 2.0	3x USB-A 5 Gbps
# of USB-C Ports / Max Data Transfer Rate	1x USB-C 5 Gbps	1x USB-C 10 Gbps	1x USB-C 10 Gbps	1x USB-C 5 Gbps	1x USB-C 5 Gbps	1x USB-C 10 Gbps	1x USB-C 10 Gbps
USB Port(s) Charging Capable	1x USB-A 7.5W	1x USB-C 7.5W 1x USB-A 7.5W	1x USB-C 15W 1x USB-A 7.5W	1x USB-C 7.5W 1x USB-A 7.5W	1x USB-C 15W 1x USB-A 7.5W	–	1x USB-C 15W 1x USB-A 7.5W
Total # of USB Ports	5	4	4	4	4	5	4

High Performance Docking Stations



Why StarTech.com



Included Power Supply is rated to provided full power to all ports and laptop charging without sharing or throttling.



Lock Slots (k-slots) for device security preventing dock and other lockable attached workstation equipment from being removed.



StarTech.com Connectivity Tools. MAC Address Pass-through, WiFi Auto Switching, Windows Layout, USB Event Monitoring (Windows only).

High Performance Docks

- Utilizes GPU Performance
- Ideal for demanding and graphic intensive applications without the need for software or compressing video.
- Driverless ensures easy deployment.

NEW



132UE-TB4USB4DOCK



TB4CDOCKUE



TB3CDK2DHUE



DK31C2DHS PDUE



MST30C2HHPDU



DK31C3MNCRUE

	132UE-TB4USB4DOCK	TB4CDOCKUE	TB3CDK2DHUE	DK31C2DHS PDUE	MST30C2HHPDU	DK31C3MNCRUE
Host Connection	Thunderbolt 4	Thunderbolt 4	Thunderbolt 3	USB-C	USB-C	USB-C
# of Monitors Supported / Max Resolution	 Up to Quad Monitors (Windows) Up to 4K 60Hz (Quad) Up to 5K 60Hz (Dual) Up to 8K 60Hz (Single, HDMI Only)	 5K 60Hz Up to 5K 60Hz (Dual) Up to 8K 30Hz	 4K 60Hz	 4K 60Hz	 4K 30Hz	 Dual 4K 60Hz Triple 4K 30Hz
Dual Display on MacBook Pro with Apple M Series Pro and Max Chips						
Video Ports	2x HDMI, 2x DP	3x TB4	2x HDMI, 2x DP	1X HDMI, 2X DP	2x HDMI, 2x HDMI/DVI Adapters	2x HDMI, 2x DP 1x USB-C DP Alt Mode
Driverless	✓	✓	✓	✓	✓	✓
OS Compatibility	Windows, macOS	Windows, macOS, ChromeOS	Windows, macOS, ChromeOS, Ubuntu	Windows, ChromeOS	Windows, ChromeOS	ChromeOS
Power Delivery	98W	98W	96W	100W	60W	60W
# of USB-A Ports / Max Data Transfer Rate	3x USB-A ^{10 Gbps} 2x USB-A ^{5 Gbps} 1x USB 2.0	3x USB-A ^{10 Gbps} 1x USB 2.0	1x USB-A ^{10 Gbps} 2x USB-A ^{5 Gbps}	2x USB-A ^{5 Gbps} 2x USB 2.0	4x USB-A ^{5 Gbps}	3x USB-A ^{10 Gbps} 2x USB 2.0
# of USB-C Ports / Max Data Transfer Rate	1x USB-C ^{10 Gbps}	3x TB4	2x USB-C ^{10 Gbps}	2x USB-C ^{10 Gbps}	1x USB-C ^{5 Gbps}	1x USB-C ^{10 Gbps} 1x USB-C ^{10 Gbps} with DP Alt Mode video
USB Port(s) Charging Capable	1x USB-C 15W 1x USB-A 7.5W	3x TB4/USB4 15W 1x USB-A 7.5W	1x USB-C 15W 1x USB-A 7.5W	2x USB-C 15W	1x USB-A 7.5W	1x USB-A 7.5W 2x USB-C 7.5W
Hardware Platform Compatibility	Apple M1 / M2 / M3 & Intel MacBook Thunderbolt 3 & TB4 Intel Thunderbolt 4 with Windows	Apple M Series & Intel MacBook Thunderbolt 3 & 4 Intel Thunderbolt 4 with Windows & Chromebooks	Apple M Series & Intel MacBook Thunderbolt 3 & 4 Intel Windows, Chromebooks	Intel Windows AMD Chromebooks with USB-C DP Alt Mode		Chromebooks with USB-C DP Alt Mode