


10 Pack 2 Port PCI Serial Adapter Cards

Product ID: 10PKPCI2S550

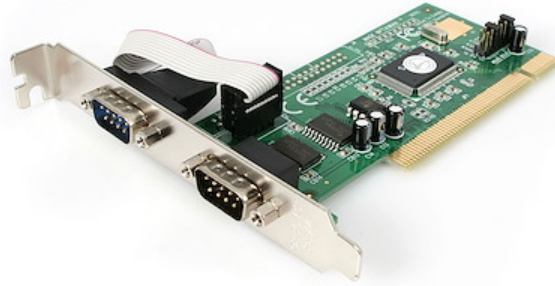

The 10PKPCI2S550 10 Pack 2 Port PCI Serial Adapter Cards lets you deploy serial connectivity across multiple computers, at a competitive price. Ideal for system builders, these cards come in non-retail packaging with a single driver disk, providing you with over 35% in savings!

Each 2 Port 16550 Serial Card can be installed in a PCI slot to add two serial ports - a cost-effective solution for connecting any new or legacy serial device, with data transfer rates of up to 115.2 Kbps.

Perfect for connecting serial modems, POS devices, PDAs, digital cameras, printers, ISDN terminal adapters and more, to your system, the adapter card supports IRQ sharing and operates flawlessly with Windows XP, Server 2003, 2000, ME, 98, 95, NT4, 3.1, DOS and Linux.

Backed by a StarTech.com lifetime warranty and free lifetime technical support.

Certifications, Reports and Compatibility

Applications

- **Manufacturing** (CNC machinery, process control equipment, bar code scanners, serial printers)
- **POS** (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)
- **Consumer** (modems, PDAs, digital cameras, printers)
- **Security** (UPS control, access key panels, video cameras, card readers, modems)
- **Casino** (video lottery terminals, slot machines)
- **Environmental Control** (lighting, temperature, clocks)

- **Healthcare** (patient monitoring equipment, nurses' stations, modems)
- **Hotel Front Desk** (serial printers, bar code scanners, keyboard, mouse, receipt printer, credit/debit card reader)
- **Hospitality/Restaurant** (credit card/debit card reader, serial printers)
- Great for OEMs, system builders or IT professionals requiring quantity serial cards for mass installations or upgrades
- **ISDN Networking**

Features

- Includes drivers for Linux and all versions of Windows
- 16 byte FIFO buffer ensures fast data transfer while multitasking
- Supports the RS-232 serial interface and the PCI bus interface
- Supports data rates up to 115.2 Kbps


Hardware

Warranty	Lifetime
Ports	2
Interface	Serial
Bus Type	PCI (5 Volt)
Card Type	Standard Profile
Port Style	Integrated on Card
Industry Standards	PCI 2.1
Chipset ID	ASIX - MCS9835CV

Performance

Serial Protocol	RS-232
Max Baud Rate	115.2 Kbps
FIFO	16 Byte

Connector(s)

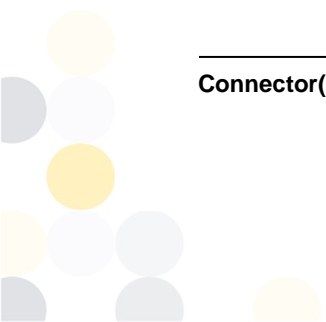

Connector Type(s)	PCI (5V, 32-bit)
External Ports	DB-9 (9 pin, D-Sub)

Software

OS Compatibility	Windows 8 (32/64bit), 7 (32/64), Vista (32/64), XP (32/64), XP Embedded, POS Ready 2009, Embedded System 2009, CE 5.0 / 6.0, 2000, 98SE, 95, DOS
	Windows Server 2012, 2008 R2, 2003(32/64)
	Linux

Environmental

Operating Temperature	0C to 70C (32F to 158F)
Storage Temperature	-40C to 85C (-40F to 185F)
Humidity	5~85% RH

Physical Characteristics

Product Length	4.7 in [12 cm]
Product Width	0.8 in [20 mm]
Product Height	4.7 in [12 cm]
Weight of Product	2.1 oz [60 g]

Packaging Information

Package Length	11.1 in [28.2 cm]
Package Width	4.3 in [11 cm]
Package Height	7.7 in [19.6 cm]
Shipping (Package) Weight	33.2 oz [940 g]

What's in the Box

Included in Package	PCI2S550 Serial Cards
	Driver CD
	Instruction Manual



****Product appearance and specifications are subject to change without notice.***

