


10 ft 1394b FireWire 800 Cable 9-9 M/M

Produkt ID: 1394\_99\_10

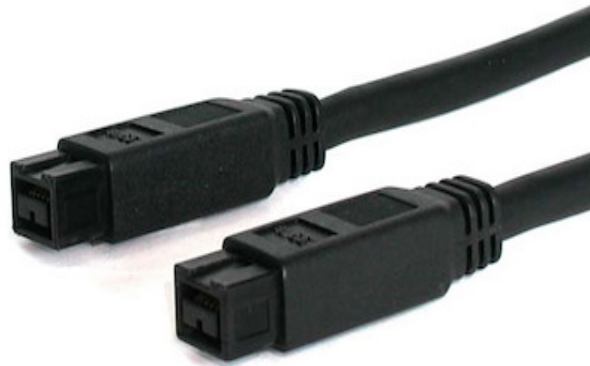

This 10ft 9-pin 1394b FireWire Cable will keep your high-bandwidth video or graphic applications moving data at up to 800 Mbps - enough for demanding high-speed digital storage and serious video capture.

StarTech.com FireWire 800 cables come with the highest quality shielding to protect your high speed data connections, and are backed by our lifetime warranty.

## Certifikat, rapporter och kompatibilitet

### Användning

- Ideal for Mass storage, Digital Video (DV), Digital Audio, Digital Cameras, Printers, Scanners, Home entertainment and other Networking products
- Connect multiple FireWire 800(1394b) compliant devices together

### Funktioner

- Hot Pluggable feature allows swapping of live devices without turning off your computer
- Compliant with FireWire800 and 1394b standards
- Compatible with all 1394b PC FireWire, Apple FireWire, and Sony iLink devices
- Supports a daisy-chain of up to 63 fireWire devices

- 9-pin cable draws power from FireWire bus
- Highest quality shielding protects from EMI (electromagnetic interference) noise
- Twisted Pair Construction
- Fast data transfer rate of up to 800 Mbits/sec

---

#### Hårdvara

Garantipolicy	Lifetime
Industristandarder	FireWire 800 & 1394b

---

#### Kontakt(er)

Connector A	FireWire 800 (9-stifts, IEEE 1394b)
Connector B	FireWire 800 (9-stifts, IEEE 1394b)

---

#### Utseende

Färg	Svart
Kabellängd	10.0 ft [3.0 m]
Produktlängd	10.0 ft [3.0 m]
Produktvikt	3.8 oz [107 g]

---

#### Förpackning

Package Length	8.0 in [20.2 cm]
Package Width	0.8 in [21.5 mm]
Package Height	8.3 in [21 cm]
Fraktvikt (förpackning)	3.8 oz [108 g]

---

#### Vad det är i lådan

Ingår i paketet	10 ft 1394b FireWire 800 Cable 9-9 M/M
-----------------	----------------------------------------

---

\* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

