


Citrix 3013936-E2 Compatible QSFP+ Module - 40GBASE-SR4 - Multi Mode Fiber (MMF) - 40GE Gigabit Ethernet QSFP+ - MPO 100m - 850nm - DDM

Product ID: 3013936-E2-ST

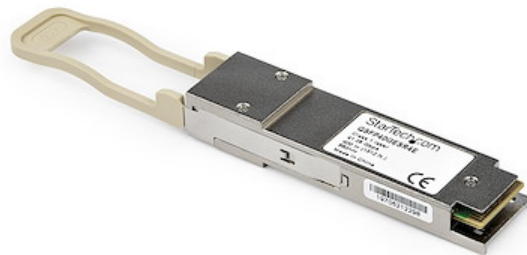

The 3013936-E2-ST is a Citrix 3013936-E2 compatible fiber transceiver module that has been designed, programmed and tested to work with Citrix brand switches and routers. It delivers dependable 40 GbE connectivity over fiber cable, for 40GBase-SR4 compliant networks, with a maximum distance of up to 100 m (328 ft).

Technical Specifications:

Wavelength: 850nm

Maximum Data Transfer Rate: 40 Gbps

Type: Multi Mode

Connection Type: MPO

Maximum Transfer Distance: 100 m (328 ft)

MTBF: 244,610,582 hours

Power Consumption: < 0.7W

This QSFP+ fiber module is hot-swappable, making upgrades and replacements seamless by minimizing network disruptions.

All StarTech.com SFP & SFP+ transceiver modules are backed by a lifetime warranty and free lifetime multilingual technical support. StarTech.com offers a wide variety of SFP modules and direct-attach SFP cables, providing the convenience and reliability you need to ensure dependable network performance.

Certifications, Reports and Compatibility

Applications

Features

- **100% CITRIX 3013936-E2 COMPATIBLE:** Designed, programmed and tested to work with compatible Citrix switches and routers to deliver dependable 40GbE connectivity
- **TECHNICAL SPECS:** 40GBASE-SR4 40 Gbps Multi Mode MPO Connector 850nm Digital Diagnostic Monitoring (DDM) Distances up to 100 m (328 ft)
- **TESTED FOR OEM HOST COMPATIBILITY:** Hot-swappable in Citrix routers and switches; DDM support reports the transceiver's status to most SNMP network management tools
- **LIFETIME WARRANTY:** Backed by a lifetime warranty on the life of the module itself - not the life of your switch. Our modules won't void your OEM warranty and supported by our Tech Advisors 5/24
- **WORKS WITH MSA COMPLIANT SWITCHES:** Also works with switch models from Ubiquiti, D-Link, Netgear, Supermicro, TP-Link and more that accept uncoded modules

Hardware

Warranty	Lifetime
Compatible Brand	Citrix

Performance

Maximum Data Transfer Rate	40.00Gbps
Max Transfer Distance	100 m (328 ft)
Type	Multi Mode
Wavelength	850nm
Compatible Networks	40 Gbps
MTBF	244,610,582 hours
Power Consumption (In Watts)	< 0.7W

Physical Characteristics

Product Length	4.8 in [12.2 cm]
Product Width	0.7 in [18.0 mm]



Product Height	0.4 in [11.0 mm]
Weight of Product	1.4 oz [40.0 g]

Packaging Information

Package Length	7.3 in [18.5 cm]
Package Width	5.1 in [13.0 cm]
Package Height	1.8 in [45.0 mm]
Shipping (Package) Weight	4.6 oz [129.0 g]

What's in the Box

Included in Package	QSFP+ Transceiver
---------------------	-------------------

**Product appearance and specifications are subject to change without notice.*

