


3.5in Black Multi Port Panel for Front Drive Bay with HD Audio - eSATA / FireWire 400 / USB 2.0

Produkt ID: 35BAYPANELHD

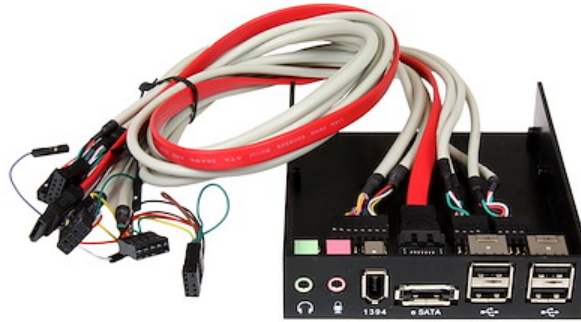


The 35BAYPANELHD Multi-Port Front Drive Bay Panel lets you access USB, eSATA, FireWire and audio ports from the front of a PC computer case, from any available 3.5" front bay, by extending the existing internal motherboard connectors to the front of the case instead of the rear.

The panel can be installed into any 3.5in front drive bay, to provide 4 USB 2.0 ports, an IEEE1394a FireWire port, an external SATA (eSATA) port and speaker and MIC ports (HD Audio and AC'97 compatible).

The 35BAYPANELHD panel is backed by 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

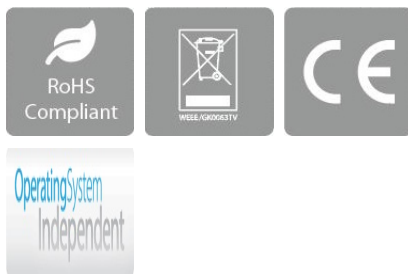

Användning

- Connecting commonly used USB, eSATA, FireWire and audio peripherals (e.g. digital cameras or camcorders, or external hard drives) to the front panel of a PC

Funktioner

- 3.5" front bay form factor (or 5.25" front bay with accessory: BRACKETFDBK)
- Compatible with AC'97 or HD Audio standards with autosensing
- 1x eSATA, 1x 6-pin FireWire, 4x USB 2.0, 2x 3.5mm Audio ports
- No driver or software installation required

Hårdvara

Garantipolicy	2 Years
Portar	8

Prestanda

Audio-specifikationer	AC'97, HD Audio
Typ och hastighet	USB 2.0 - 480 Mbit/s SATA II (3 Gbps)

Kontakt(er)

Interna portar	5 - IDC (10-stifts, moderkortskontakt)
	1 - SATA (7-stifts, data)
Externa portar	2 - 3.5 mm minijack (3-polig)
	1 - eSATA (7-stifts, data)
	1 - FireWire 400 (6-stifts, IEEE 1394a)
	4 - USB 2.0 Type-A (4 stift, 480 Mbps)

Mjukvara

OS-kompatibilitet	Operating System independent
-------------------	------------------------------

Särskilda anmärkningar/krav

System- och kabelkrav	Available 3.5" front bay One available SATA connector on motherboard or internal SATA card
-----------------------	---

Two available USB headers on motherboard or internal USB card

AC '97 or HD Audio compatible internal audio header

One available FireWire header on motherboard or external FireWire 6-pin connector

Utseende

Färg	Svart
Kabinetttyp	Av plast
Kabellängd	23.6 in [60 cm]
Produktlängd	4.0 in [10.2 cm]
Produktbredd	1.0 in [2.5 cm]
Produkthöjd	4.8 in [12.1 cm]
Produktvikt	8.8 oz [250 g]

Förpackning

Förpackningsantal	1
Paketets längd	9.4 in [23.8 cm]
Paketets bredd	1.7 in [44 mm]
Paketets höjd	5.3 in [13.5 cm]
Fraktvikt (förpackning)	11.3 oz [320 g]

Vad det är i lådan

Ingår i paketet	1 - 3.5" Front Bay Panel
	1 - 6-pin FireWire to Header Cable
	1 - Screw Kit
	1 - Instruction Manual

Warranty Information

Warranty	2 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.