


## Cat5e Patch Cable with Snagless RJ45 Connectors - 2m, Yellow

**Product ID:** 45PAT2MYL

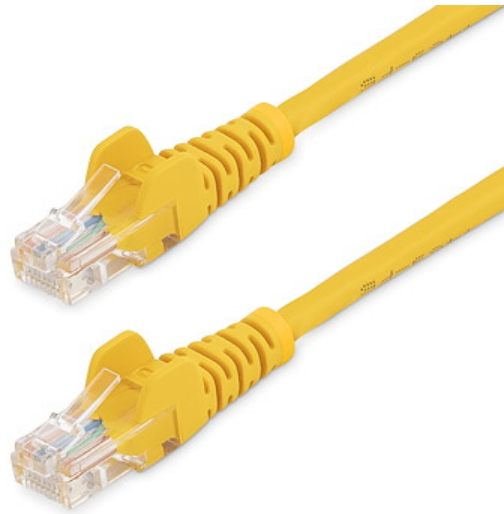

The 45PAT2MYL Cat5e patch cable (2m) meets or exceeds all Cat 5e cable specifications to ensure reliable Ethernet network connections, and features a durable yellow PVC jacket that enables you to color code your network cable runs as needed.

To ensure long-lasting performance, this high quality Cat5e patch cable features a snagless design that protects the RJ45 connector clips from damage and makes the cable less prone to snagging during installation. The cable also features molded PVC strain relief that prevents the RJ45 connector termination points from bending at sharp angles, reducing the risk of cable failure.

Constructed of only top quality materials, this Cat5e patch cord delivers reliable performance and is backed by our lifetime warranty.

Get the highest value for your cable investment with our Cat 5e cables, each one manufactured using high-quality copper conductors.

Ensure high-performance capability for your demanding Ethernet applications, such as Power-over-Ethernet, using cables that include 24 AWG copper.

Rely on our RJ45 connectors to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

### Certifications, Reports and Compatibility



### Applications

- Designed for use with Fast Ethernet networks
- Patches from hub to distribution panel
- Connects workstation to wall outlet

## Features

- RJ45 connector clip protectors
- Carefully constructed and tested, to keep Near End Crosstalk (NEXT) well within acceptable limits
- Colored hoods for departmental color coding
- Molded strain relief prevents the cable from being bent at sharp angles at the RJ45 connector, to minimize the stress at the plug termination point
- Constructed with top quality components
- High quality 24 AWG copper wire

---

### Hardware

Warranty	Lifetime
Number of Conductors	4 pair UTP
Cable Jacket Material	PVC - Polyvinyl Chloride
Fire Rating	CM Rated
Cable Type	Snagless

---

### Performance

Cable Rating	CAT5e - 350 MHz
--------------	-----------------

---

### Connector(s)

Connector A	1 - RJ-45
Connector B	1 - RJ-45

---

### Environmental

Operating Temperature	0C to 30C (32F to 86F)
Storage Temperature	-20C to 60C (-4F to 140F)
Humidity	0 ~ 60% RH

---

**Physical Characteristics**

Color	Yellow
Wire Gauge	24 AWG
Conductor Type	Stranded Copper
Cable Length	6.6 ft [2 m]
Product Length	6.6 ft [2.0 m]
Product Width	0.5 in [1.2 cm]
Product Height	0.6 in [1.4 cm]
Weight of Product	2.5 oz [71.0 g]

---

**Packaging Information**

Package Quantity	1
Package Length	8.7 in [22.0 cm]
Package Width	7.9 in [20.0 cm]
Package Height	0.7 in [1.7 cm]
Shipping (Package) Weight	2.8 oz [79.0 g]

---

**What's in the Box**

Included in Package	1 - 2m Yellow Snagless Cat5e UTP Patch Cable
---------------------	--

---

***\*Product appearance and specifications are subject to change without notice.***