


Cat5e Ethernet Patch Cable with Snagless RJ45 Connectors - 7 m, White

Product ID: 45PAT7MWH

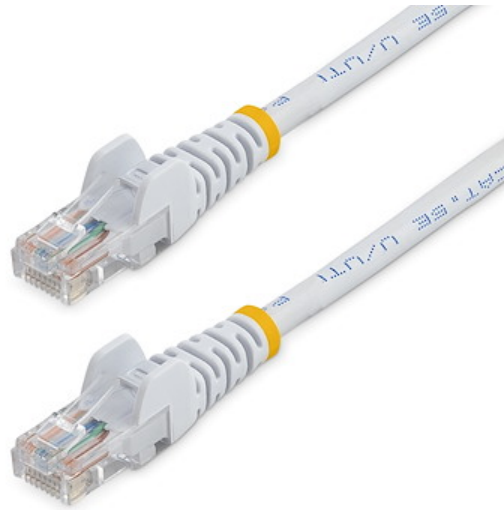

This Cat5e patch cable delivers reliable network connections, which ensures high-performance capability for your demanding Ethernet applications.

This 7-meter white network cable is perfect for use in network conduits and raceways. The cable is intended for longer distance applications, such as running up a post or throughout the office from a hub to a wall- jack.

For easier network installations, our Cat 5e cables are available in a wide variety of lengths and colors. This ensures you have the right size of cable available when you need it and it lets you color code your connections for a more organized setup.

For trouble-free cable runs, this durable cable features snagless connectors that protect the RJ45 clips during installation, making them less likely to snag or break.

The cable also features moulded boots which offer connector strain relief by stopping the RJ45 connector termination points from bending at sharp angles. This reduces the risk of damage to the cable, which could decrease network connectivity and performance.

Get the highest value for your cable investment with our Cat5e Ethernet cables, each one manufactured using high-quality copper conductors. They are carefully constructed and tested, to keep Near-End Crosstalk (NEXT) well within acceptable limits.

Ensure high-performance capability for your demanding Ethernet applications, such as Power-over-Ethernet and 4K or 1080p video streaming, using cables that include 24 AWG copper.

You can rely on our RJ45 connectors to deliver optimum conductivity, while eliminating signal loss due to oxidation or corrosion.

The 45PAT7MWH is backed by StarTech.com's lifetime warranty for guaranteed reliability.

Certifications, Reports and Compatibility



Applications

- Designed for use with Fast Ethernet networks
- Connect between computers, hubs, switches, print servers and patch panels
- Connects workstation to wall outlet

Features

- RJ45 connector-clip protectors eliminate cable snags and breaks during installation
- White PVC jacket for color coding your connections
- 7 meters in length for longer connections
- Moulded RJ45 connectors prevent cable damage and also provide strain relief
- 50-micron gold-plated connectors for a clear signal
- High-quality 24 AWG copper wire

Hardware

| | |
|-----------------------|--------------------------|
| Warranty | Lifetime |
| Number of Conductors | 4 pair UTP |
| Cable Jacket Material | PVC - Polyvinyl Chloride |
| Fire Rating | CM Rated |
| Cable Type | Snagless |

Performance

| | |
|--------------|-----------------|
| Cable Rating | CAT5e - 350 MHz |
|--------------|-----------------|

Connector(s)

| | |
|-------------|-----------|
| Connector A | 1 - RJ-45 |
| Connector B | 1 - RJ-45 |

Environmental

| | |
|-----------------------|---------------------------|
| Operating Temperature | 0C to 30C (32F to 86F) |
| Storage Temperature | -20C to 60C (-4F to 140F) |
| Humidity | 0 ~ 60% RH |

Physical Characteristics

| | |
|-------------------|------------------|
| Color | White |
| Wire Gauge | 24 AWG |
| Conductor Type | Stranded Copper |
| Cable Length | 23.0 ft [7 m] |
| Product Length | 23.0 ft [7.0 m] |
| Product Width | 0.5 in [1.3 cm] |
| Product Height | 0.6 in [1.6 cm] |
| Weight of Product | 8.8 oz [248.0 g] |

Packaging Information

| | |
|---------------------------|-------------------|
| Package Quantity | 1 |
| Package Length | 13.0 in [33.0 cm] |
| Package Width | 10.0 in [25.5 cm] |
| Package Height | 0.8 in [2.0 cm] |
| Shipping (Package) Weight | 9.3 oz [264.0 g] |

What's in the Box

| | |
|---------------------|-----------------------|
| Included in Package | 1 - Cat5e patch cable |
|---------------------|-----------------------|

****Product appearance and specifications are subject to change without notice.***