


Six-Monitor Desk Mount with Crossbar, Up To 32-inch Computer Screens, Max 17.6lb (8kg) each, Dual Column, C-clamp/Grommet, Height Adjustable

Product ID: 6-MONITOR-ARM-A

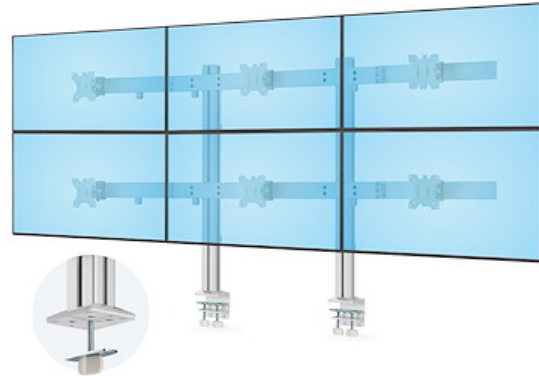

This monitor desk mount is designed to support up to six 32-inch displays, creating an ergonomic multi-monitor setup that provides a vast viewing area for productivity.

The dual-column design, sturdy aluminum construction, and enhanced c-clamp base ensure long-lasting stability. This design prevents tilting over time and evenly distributes weight across the desk for reliable support.

This monitor setup is ideal for data aggregation and monitoring applications such as financial analysis, security monitoring, control rooms, and other activities that require an extensive viewing area.

Individual micro-height adjustment enables precise alignment of each monitor.

The ergonomic VESA plate support $\pm 17^\circ$ swivel, $\pm 34^\circ$ tilt, and 360 screen rotation for portrait or landscape orientation, and 75x75/100 patterns. Each display mount can support up to 17.6lb (8kg).

Every monitor can be positioned along the 71.1-inch (1.8m) wide crossbars. The outer monitors can be angled ($\pm 16^\circ$) toward the user.

The mount offers dual mounting options: robust C-clamps for desks from 0.4 to 2.9in (1 to 7.5cm) thick or grommet hole mounts for desks from 0.4 to 1.7in (1 to 4.5cm) thick.

Each crossbar can be positioned along the two 33.5-inch (85.3cm) columns, providing flexible height options.

All VESA plates are removable for easy installation or removal of the monitors.

To maintain an organized workspace, the mount includes cable clips for the crossbars and columns to keep cables neatly tucked away and out of sight. Combine accessories such as cable ties and hooks (parts HKLP25GN and CBMZT8B) for a tidier setup.

Certifications, Reports and Compatibility

Applications

Features

- **SIX-MONITOR MOUNT:** Crossbar design ensures a stable horizontal alignment of the monitors at all times for a seamless visual experience; Six adjustable VESA 75x75/100x100 mounts for up to 32" & 17.6lb (8kg) per screen; Aluminum and steel construction
- **DUAL COLUMN STABILITY:** Robust dual column monitor mount with improved base design that won't tilt over time, for a secure & rigid multi-monitor mounting solution; It ensures the weight is more evenly distributed across the desk improving overall stability
- **PERFECT 3X2 SETUP:** Individual micro-height adjustment for precise alignment of each monitor; The outer monitors can be angled (+/-16) toward the user; Each row of screens can be height adjusted along the 34-inch (86.3cm) columns (tools included)
- **DISPLAY ADJUSTMENTS:** VESA plates support +/-17 swivel, +/-34 tilt, and 360 screen rotation for portrait/landscape; Ergonomic mount allow moving monitors along the 5.9ft (1.8m) wide crossbars
- **VERSATILE INSTALLATION:** C-clamp design for 0.4-2.9in (1–7.5cm) thick desks or grommet hole mounts for 0.4-1.7in (1–4.5cm) thick desks; Removable VESA plates for convenient monitor installation/removal; Cable management clips for the crossbars and columns

Hardware

Warranty	5 Years
Wallmountable	No
Cable Management	Yes
Tools Included	Yes
Articulating	Yes
# of Displays Supported	6
Mounting Options	Desk & Grommet Clamp
VESA Hole Pattern(s)	75x75 mm 100x100 mm
Aspect Ratio	16:9
Mounting Surface	Desk Clamp: Thickness 0.8 - 2.3in (2 - 7.5cm) , Grommet Clamp:

Thickness Thickness 0.4 - 1.7in (1 - 4.5cm)

Performance

Weight Capacity (Per Display)	17.6 lb [8 kg]
Minimum Display Size	17"
Maximum Display Size	32"
Fits Curved Display	No
Fits UltraWide Displays	No
Height Adjustment	Yes
Maximum Height	34.0 in [863 mm]
Maximum Arm Extension	68.7 in [174.5 cm]
Display Tilt	+34 / -34
Display Swivel	+ 17 / - 17
Display Rotation	360
Anti-theft	No

Physical Characteristics

Color	White
Construction Material	Steel and Plastic
Product Length	4.6 in [11.8 cm]
Product Width	5.9 ft [1.8 m]
Product Height	34.0 in [86.3 cm]
Weight of Product	30.8 lb [14.0 kg]

Packaging Information

Package Quantity	1
Package Length	15.9 in [40.5 cm]
Package Width	3.4 ft [1.0 m]

Package Height	4.7 in [12.0 cm]
Shipping (Package) Weight	34.8 lb [15.8 kg]

What's in the Box

Included in Package	2 - Desk Clamps
	2 - Grommet, Base Plates
	2 - Grommet, Clamping Plates
	2 - Columns
	2 - Center, Crossbars
	2 - Left, Crossbars
	2 - Right, Crossbars
	4 - Crossbar Mounting Brackets
	6 - VESA Brackets
	6 - VESA Bracket Screws
	4 - Column Cable Management Clips
	8 - Crossbar Cable Management Clips
	2 - Column Endcaps
	2 - Base Caps
	10 - Clamp Pads
	8 - Base Screws
	16 - Center Crossbar Screws
	8 - Button Head L&R Crossbar Screws
	4 - Socket Head L&R Crossbar Screws
	1 - Bubble Level
	1 - 4mm Hex Key
	1 - 5mm Hex Key

- 1 - 6mm Hex Key
- 24 - M4x12mm Screws
- 24 - M4x16mm Screws
- 24 - M5x12mm Screws
- 24 - M5x16mm Screws
- 24 - Spacers
- 24 - Washers
- 1 - User Manual

**Warranty
Information**

Warranty

5 Years

****Product appearance and specifications are subject to change without notice.***