

## Bluetooth Audio Receiver with NFC - Wireless Audio

**Product ID:** BT2A



StarTech.com

The BT2A Bluetooth audio receiver turns your home stereo, or any audio output device into a Bluetooth-compatible media gateway you can use for wirelessly streaming music directly from a Bluetooth-enabled device, such as your Smartphone, Tablet, or iPod Touch.

The Bluetooth receiver delivers hassle-free pairing using NFC (Near field communication) -- gently tap your NFC-enabled Bluetooth device on the BT2A and your device will be ready to transmit audio wirelessly through your audio equipment, with no additional configuration required.

To ensure the best sound quality, the BT2A features a Wolfson Digital-to-Analog converter (DAC). Plus, for simple compatibility with your existing devices, the receiver includes analog cabling for connections that require 2-channel RCA audio, or 3.5mm audio.

The BT2A is backed by a StarTech.com 2-year warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

### Applications

- Wirelessly stream music from your mobile phone to your home stereo
- Quickly switch between audio output devices using NFC

### Features

- NFC Support
- Wolfson DAC

- aptX Audio Codec
- 3.5mm Audio cable included
- 2-CH RCA audio adapter included
- Compatible with A2DP stereo Bluetooth devices
- Digital Audio output (Toslink)

---

### Prominence

Warranty	2 Years
Description CDW 75 - 1st Line	StarTech.com Wireless Bluetooth Audio Receiver with NFC and Wolfson DAC

---

### Hardware

AV Input	Bluetooth
AV Output	3.5 mm Audio
Audio	Yes
Industry Standards	NFC aptX
Chipset ID	Wolfson - WM8524 DAC

---

### Performance

Audio Specifications	2 Channel Stereo Audio
----------------------	------------------------

---

### Connector(s)

Connector Type(s)	Bluetooth Class 2.0
Connector A	Bluetooth Class 2.0
Connector B	Toslink (SPDIF, Optical) 3.5 mm Mini-Jack (3 Position)

---


### Indicators

LED Indicators	1 x Pair LED
----------------	--------------

---

### Power

Power Source	AC Adapter Included
--------------	---------------------

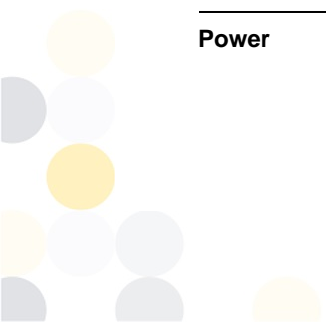

Input Voltage	100 - 240 AC
Input Current	300mA
Output Voltage	5 DC
Output Current	1A
Center Tip Polarity	Positive
Plug Type	M
Power Consumption (In Watts)	5

---

#### Environmental

Operating Temperature	0C to 43C (32F to 109F)
Storage Temperature	-20C to 60C (-4F to 140F)
Humidity	50~70%

---

#### Physical Characteristics

Color	Black
Material	Plastic
Product Length	3.0 in [77.0 mm]
Product Width	3.3 in [84.0 mm]
Product Height	1.0 in [26.0 mm]
Weight of Product	1.9 oz [55.0 g]

---

#### Packaging Information

Package Quantity	12
Package Length	2.5 in [64.0 mm]
Package Width	4.8 in [12.2 cm]
Package Height	9.5 in [24.2 cm]
Shipping (Package) Weight	13.0 oz [367.0 g]

---

**What's in the  
Box**

Included in Package	Bluetooth Audio Receiver
	3.5mm Audio Cable (M/M)
	RCA Breakout Cable
	Universal Power Adapter (NA/UK/EU)
	USB power cable
	User manual

---

***\*Product appearance and specifications are subject to change without notice.***

