


Shielded Cat 6a Keystone Jack - RJ45 Ethernet Cat6a Wall Jack White - 110 Type

Product ID: C6AKEY110WH

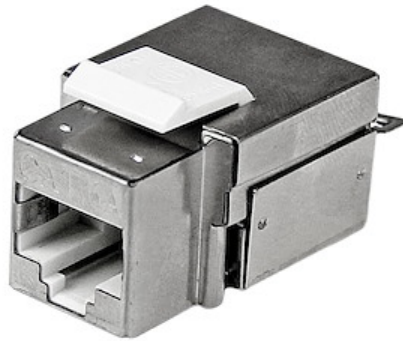

The C6AKEY110WH Cat 6a Keystone Jack is designed to snap into wall plates, patch panels, and surface connection boxes for quick, seamless deployment.

Meeting and exceeding the international standard ISO / IEC 11801 and the ANSI/TIA-568-C.2 requirements, this RJ45 keystone jack provides the perfect solution for your Ethernet networks.

Durably constructed of only top quality materials, this Cat6a wall jack is backed by StarTech.com's 2 year warranty.

Certifications, Reports and Compatibility



Applications

- Suitable for applications that use 23-26 AWG solid state and stranded network cables
- 1000BASE-Tx Gigabit Ethernet, 100BASE-TX Fast Ethernet, 10BASE-T Ethernet applications
- ATM-25/ATM-51/ATM-155 network connections
- 100 VG-AnyLan network connections
- TR-4/TR-16 Active/TR16 Passive network connections

Features

- Flame retardant (UL 94V0) plastic housing
- Supports Cat6a Network Bandwidths of 500MHz
- Meets and exceeds the international standard ISO / IEC 11801 and the ANSI/TIA-568-C.2 requirements
- Color coded for both T568A and T568B installations

Connector(s)

Warranty	2 Years
Connector Type(s)	1 - RJ-45

Physical Characteristics

Color	White
Product Length	1.5 in [3.8 cm]
Product Width	0.8 in [2.1 cm]
Product Height	0.6 in [1.6 cm]
Weight of Product	0.4 oz [11.0 g]

Packaging Information

Package Quantity	1
Package Length	4.9 in [12.5 cm]
Package Width	3.5 in [9.0 cm]
Package Height	0.6 in [1.4 cm]
Shipping (Package) Weight	0.5 oz [13.0 g]

What's in the Box

Included in Package	1 - Shielded Cat 6a RJ45 Keystone Jack White - 110 Type
---------------------	---

****Product appearance and specifications are subject to change without notice.***