

35 ft Cat 6 White Molded RJ45 UTP Gigabit Cat6 Patch Cable - 35ft Patch Cord

Productcode: C6PATCH35WH



The C6PATCH35WH Cat 6 Patch Cable (35 ft) meets or exceeds all Category 6 cable specifications to ensure reliable Gigabit network connections, and features a durable white PVC jacket that enables you to color code your network cable runs as needed.

To ensure long-lasting performance, this high quality Cat 6 patch cable features molded PVC strain relief that prevents the RJ45 connector termination points from bending at sharp angles - reducing the risk of cable damage, which could decrease network performance.


Constructed of only top quality materials, this Gigabit Patch Cable delivers reliable performance and is backed by our Lifetime Warranty.

StarTech.com Cat6 cables are manufactured using high-quality copper conductors. While many cable manufacturers offer a "cheaper" cable, based on a copper-coated aluminum core, we make no compromises on quality to ensure you receive top value and performance for your network cable investment.

This Cat6 cable is constructed with 24 gauge copper wire, to support a broad range of Ethernet applications such as Power over Ethernet (PoE). Because we use a high quality copper wire, our cables easily sustain the power required for Power over Ethernet applications, whereas the inferior quality offered by copper-coated aluminum cables may be subject to insufficient power delivery, heat buildup, equipment damage and potentially, fire.

This molded patch cable offers high quality connectors comprised of 50-micron gold, to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

Certificaties, rapporten en compatibiliteit

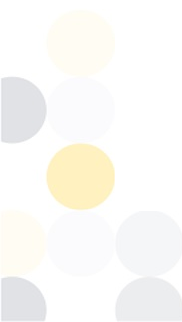

Toepassingen

- Designed for use with Gigabit networks
- Patches from hub to distribution panel
- Connects workstation to wall outlet
- Extend the reach of your Gigabit network devices by 35 ft

Eigenschappen

- Molded RJ45 connectors
- Carefully constructed and tested, to keep Near End Crosstalk (NEXT) well within acceptable limits
- Colored hoods for departmental color coding
- Constructed with top quality components
- High quality 24 AWG copper wire
- ETL Verified

Hardware

| | |
|--------------------|---------------------------------|
| Garantiebeleid | Lifetime |
| Aantal geleiders | 4 pair UTP |
| Type kabelmantel | PVC - Polyvinyl Chloride |
| Brandbestendigheid | CMG goedgekeurd (algemeen doel) |
| Type kabel | Gegoten |
| Kabelstandaard | TIA/EIA-568-B.1-2001 T568B |

Prestaties

| | |
|-------------------|----------------|
| Kabelspecificatie | CAT6 - 500 MHz |
|-------------------|----------------|

Connector(en)

| | |
|-------------|-------|
| Connector A | RJ-45 |
| Connector B | RJ-45 |

Fysieke eigenschappen

| | |
|----------------|------------------|
| Kleur | Wit |
| Draaddikte | 24 AWG |
| Kabellengte | 35.0 ft [10.7 m] |
| Lengte product | 35.0 ft [10.7 m] |

Verpakkingsinformatie

| | |
|--------------------------|-----------------|
| Package Length | 9.8 in [25 cm] |
| Package Width | 1.1 in [28 mm] |
| Package Height | 12.6 in [32 cm] |
| Verzendgewicht (verpakt) | 15.5 oz [440 g] |

Wat wordt er meegeleverd

| | |
|-------------|--|
| Meegeleverd | 35 ft White Molded Cat6 UTP Patch Cable - ETL Verified |
|-------------|--|

* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.

