


## 3ft CAT6 Ethernet Cable - Red CAT 6 Gigabit Ethernet Wire -250MHz 100W PoE RJ45 UTP Molded Network/Patch Cord w/Strain Relief/ Individually Tested

ID prodotto: C6PATCH3RD

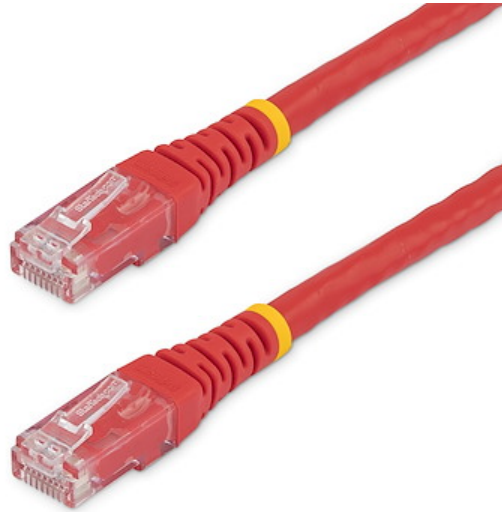

The C6PATCH3RD Cat 6 Patch Cable (3 ft) meets or exceeds all Category 6 cable specifications to ensure reliable Gigabit network connections, and features a durable red PVC jacket that enables you to color code your network cable runs as needed.

To ensure long-lasting performance, this high quality Cat 6 patch cable features molded PVC strain relief that prevents the RJ45 connector termination points from bending at sharp angles - reducing the risk of cable damage, which could decrease network performance.

Constructed of only top quality materials, this Gigabit Patch Cable delivers reliable performance and is backed by our Lifetime Warranty.

StarTech.com Cat6 cables are manufactured using high-quality copper conductors. While many cable manufacturers offer a "cheaper" cable, based on a copper-coated aluminum core, we make no compromises on quality to ensure you receive top value and performance for your network cable investment.

This Cat6 cable is constructed with 24 gauge copper wire, to support a broad range of Ethernet applications such as Power over Ethernet (PoE). Because we use a high quality copper wire, our cables easily sustain the power required for Power over Ethernet applications, whereas the inferior quality offered by copper-coated aluminum cables may be subject to insufficient power delivery, heat buildup, equipment damage and potentially, fire.

This molded patch cable offers high quality connectors comprised of 50-micron gold, to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

Our Cat6 Ethernet Cables are ETL Verified to meet ANSI/TIA-568.2-D standards, ensuring peak performance for high-speed 10G applications. Independent testing confirms compliance with strict insertion loss, return loss, and crosstalk limits, maintaining stable signal transmission over longer

runs. The STP shielding is verified for EMI resistance, for guaranteed reliability in demanding environments.

## Certificazioni, report e compatibilità



## Applicazioni

- Progettato per l'utilizzo con reti Gigabit
- Consente il collegamento dall'hub al pannello di distribuzione
- Consente il collegamento della workstation alla presa a muro

## Caratteristiche

- Filo in rame AWG 24 di alta qualità
- Certificato ETL
- Connettori RJ45 modellati
- Accuratamente realizzato e testato per mantenere le interferenze near-end (NEXT) ampiamente entro i limiti accettabili
- Cappucci colorati per codifica dei colori a sezioni

---

### Hardware

|                               |                            |
|-------------------------------|----------------------------|
| Norme di garanzia             | Lifetime                   |
| Numero di conduttori          | 4 Pair UTP                 |
| Tipo guaina cavo              | PVC - Polyvinyl Chloride   |
| Classe di resistenza al fuoco | Classe CMG (uso generale)  |
| Standard cablaggio            | TIA/EIA-568-B.1-2001 T568B |

---

### Prestazioni

|                             |                              |                                  |
|-----------------------------|------------------------------|----------------------------------|
|                             | Certificato ETL              | Sì                               |
|                             | Classe cavo                  | CAT6 - 250 MHz                   |
| <hr/>                       |                              |                                  |
| Connettore/i                | Connettore A                 | 1 - RJ-45                        |
|                             | Connettore B                 | 1 - RJ-45                        |
| <hr/>                       |                              |                                  |
| Caratteristiche fisiche     | Colore                       | Rosso                            |
|                             | Diametro filo                | 24 AWG                           |
|                             | Tipo di conduttore           | Rame intrecciato                 |
|                             | Lunghezza del cavo           | 3.0 ft [0.9 m]                   |
|                             | Lunghezza prodotto           | 3.0 ft [0.9 m]                   |
|                             | Peso prodotto                | 1.6 oz [44 g]                    |
| <hr/>                       |                              |                                  |
| Informazioni confezione     | Quantità confezione          | 1                                |
|                             | Lunghezza Confezione         | 7.0 in [17.8 cm]                 |
|                             | Larghezza del Pacco          | 7.8 in [19.9 cm]                 |
|                             | Altezza del Pacco            | 0.6 in [1.6 cm]                  |
|                             | Peso spedizione (confezione) | 2.0 oz [58.0 g]                  |
| <hr/>                       |                              |                                  |
| Contenuto della confezione  | Incluso nella confezione     | 1 - 3 ft. Cat6 Patch Cable - Red |
| <hr/>                       |                              |                                  |
| Informazioni sulla garanzia | Warranty                     | A vita                           |
| <hr/>                       |                              |                                  |

\* L'aspetto e le specifiche dell'articolo sono soggetti a modifiche senza preavviso.