


3ft CAT6 Ethernet Cable - Red CAT 6 Gigabit Ethernet Wire -250MHz 100W PoE RJ45
UTP Molded Network/Patch Cord w/Strain Relief/ Individually Tested

Productcode: C6PATCH3RD

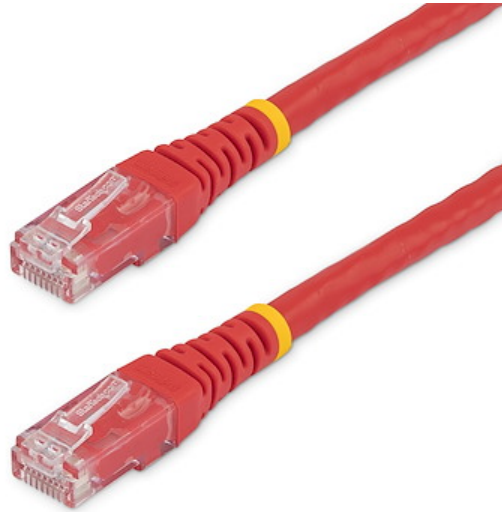

The C6PATCH3RD Cat 6 Patch Cable (3 ft) meets or exceeds all Category 6 cable specifications to ensure reliable Gigabit network connections, and features a durable red PVC jacket that enables you to color code your network cable runs as needed.

To ensure long-lasting performance, this high quality Cat 6 patch cable features molded PVC strain relief that prevents the RJ45 connector termination points from bending at sharp angles - reducing the risk of cable damage, which could decrease network performance.

Constructed of only top quality materials, this Gigabit Patch Cable delivers reliable performance and is backed by our Lifetime Warranty.

StarTech.com Cat6 cables are manufactured using high-quality copper conductors. While many cable manufacturers offer a "cheaper" cable, based on a copper-coated aluminum core, we make no compromises on quality to ensure you receive top value and performance for your network cable investment.

This Cat6 cable is constructed with 24 gauge copper wire, to support a broad range of Ethernet applications such as Power over Ethernet (PoE). Because we use a high quality copper wire, our cables easily sustain the power required for Power over Ethernet applications, whereas the inferior quality offered by copper-coated aluminum cables may be subject to insufficient power delivery, heat buildup, equipment damage and potentially, fire.

This molded patch cable offers high quality connectors comprised of 50-micron gold, to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

Our Cat6 Ethernet Cables are ETL Verified to meet ANSI/TIA-568.2-D standards, ensuring peak performance for high-speed 10G applications. Independent testing confirms compliance with strict insertion loss, return loss, and crosstalk limits, maintaining stable signal transmission over longer

runs. The STP shielding is verified for EMI resistance, for guaranteed reliability in demanding environments.

Certificaties, rapporten en compatibiliteit



Toepassingen

- Ontworpen voor gebruik met Gigabit-netwerken
- Voor het verbinden van een hub met een distributiepaneel
- Voor het verbinden van een werkstation met een wandcontactdoos

Eigenschappen

- Hoogwaardig koperdraad met 0,5 mm dikte
- ETL-geverifieerd
- Gegoten RJ45-connectoren
- Zorgvuldig ontworpen en gefabriceerd om Near End Crosstalk (NEXT) binnen aanvaardbare grenzen te houden
- Gekleurde afscherming voor eventuele kleurcodering

Hardware

Garantiebeleid	Lifetime
Aantal geleiders	4 Pair UTP
Type kabelmantel	PVC - Polyvinyl Chloride
Brandbestendigheid	CMG goedgekeurd (algemeen doel)
Kabelstandaard	TIA/EIA-568-B.1-2001 T568B

Prestaties

ETL-geverifieerd	Ja
------------------	----

	Kabelspecificatie	CAT6 - 250 MHz
Connector(en)	Connector A	1 - RJ-45
	Connector B	1 - RJ-45
Fysieke eigenschappen	Kleur	Rood
	Draaddikte	24 AWG
	Type geleider	Gevlochten koper
	Kabellengte	3.0 ft [0.9 m]
	Lengte product	3.0 ft [0.9 m]
	Gewicht product	1.6 oz [44 g]
Verpakkingsinformatie	Verpakkingsaantal	1
	Lengte Verpakking	7.0 in [17.8 cm]
	Breedte Verpakking	7.8 in [19.9 cm]
	Hoogte Verpakking	0.6 in [1.6 cm]
	Verzendgewicht (verpakt)	2.0 oz [58.0 g]
Wat wordt er meegeleverd	Meegeleverd	1 - 3 ft. Cat6 Patch Cable - Red
Garantiebepalingen	Warranty	Levenslang

* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.