


20 Pack Cable Raceway Inside Corner Connectors for CBMWD3816 - Cable Management Accessories - Channel Raceway Fitting - Wiring Duct 90 Degree Inside Elbow - Plastic - UL  
Product ID: CBMWD3816I

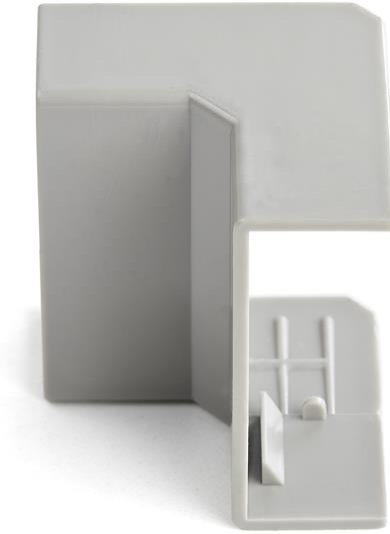

This 20-pack of raceway inside elbows work with the StarTech.com CBMWD3816 raceway system.

Use these cable raceway inside elbows with the StarTech.com CBMWD3816 raceway to join two of them together at a 90 degree angle to extend the length of your raceway inside corners of your office or server room.

Made from sturdy self-extinguishing ABS that's also warp proof, these wiring duct elbow connectors are UL approved with 94HB Flamability (Horizontal Burning) Rating.

Combine this inside elbow with other StarTech.com CBMWD3816 raceway system accessories to give your cable management solution a finished look.

The Coupler (CBMWD3816C) (20-Pack), joins two raceways together and extends the length of your raceway.

The End Piece (CBMWD3816E) (20-Pack), cleanly caps off the end of your raceway.

The Lateral Elbow (CBMWD3816L) (20-Pack), joins two raceways together and runs them up the wall at a 90 degree angle.

The Outside Elbow (CBMWD3816O) (20-Pack), joins two raceways together around corners at a 90 degree angle.

The T Connector (CBMWD3816T) (20-Pack), joins three raceways together in T-bar.

These cable management raceway inside elbows are TAA compliant and backed by a StarTech.com Lifetime warranty and free 24/5 technical support. StarTech.com has been the IT professionals choice for over 30 years.

## Certifications, Reports and Compatibility





## Applications

- Protects cables from damage while neatly routing them in your office or server room

## Features

- **GIVE YOUR CABLE MANAGEMENT RACEWAY A FINISHED LOOK:** Use cable raceway inside corner connectors (20 pack) w/StarTech.com CBMWD3816 raceways to join them together inside corners in your workspace
- **INDUSTRIAL STRENGTH:** Made from sturdy warp-proof ABS, these inside elbow cable/wiring duct connectors are UL approved with 94HB Flamability (Horizontal Burning) Rating, self-extinguishing
- **OTHER RACEWAY ACCESSORIES:** Coupler (CBMWD3816C), End Piece (CBMWD3816E), Lateral Elbow (CBMWD3816L), Outside Elbow (CBMWD3816O), T Connector (CBMWD3816T); sold separately
- **TECHNICAL SPECIFICATIONS:** 90° Angle Connector Width: 1.49" (38mm) Connector Height: 0.63" (16mm) White UL approved UL 94HB rated RoHS
- **STARTECH.COM ADVANTAGE:** IT professionals choice for over 30 years; These raceway inside elbows are backed for life by StarTech.com, including free 24/5 North America based multi-lingual tech support

<b>Physical Characteristics</b>	Warranty	2 Years
	Color	White
	Material	ABS
	Product Length	1.4 in [35.95 mm]
	Product Width	1.6 in [41.34 mm]
	Product Height	1.4 in [35.95 mm]
	Weight of Product	0.2 oz [6 g]
<b>Packaging Information</b>	Package Length	4.7 in [12.2 cm]
	Package Width	9.6 in [24.4 cm]
	Package Height	1.7 in [42.7 mm]
	Shipping (Package) Weight	4.5 oz [128 g]
<b>What's in the Box</b>	Included in Package	Inside Elbow Connectors

*\*Product appearance and specifications are subject to change without notice.*