

10/100 Mbps Multi Mode Fiber Media Converter SC 2 km

Produkt ID: ET90110SC2



The ET90110SC2 10/100 Mbps Multimode Fiber Media Converter SC (2 km) lets you extend a Fast Ethernet network (10/100Mbps) over multimode fiber, at distances up to 2 km (1.2 miles).

A cost-effective solution for connecting a 10/100 Mbps Ethernet (10/100Base-T) network to remote network segments over a 100Base-FX fiber backbone, the media converter is designed to offer a durable and convenient Ethernet-to-fiber solution, featuring an all-steel chassis, and a simple plug-and-play installation with minimal configuration required.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

Användning

- Provides connectivity to a user or network segment that is in an isolated area of a large complex or in another building altogether
- Perfect for secure environments required by government agencies where EMI is not acceptable
- Connect traffic control/monitoring systems at extreme distances to the main office
- Extend network connectivity to remote areas of stadiums, auditoriums or other venues
- Converts 10/100Base-T Ethernet to 100Base-FX fiber optic signals over multimode fiber cable

Funktioner

- Supports standalone operation, or installation into the ETCHS2U Rackmount Chassis
- Advanced features include Link-loss forwarding, remote status monitoring, two frame lengths
- Supports a maximum fiber cable length of 2 km
- Supports full or half-duplex operation
- Easy to use and install

Hårdvara

Garantipolicy	2 Years
PoE	Nej
WDM	Nej
Industristandarder	IEEE802.3 (10BASE-T) IEEE802.3u (100BASE-TX) IEEE802.3u (100BASE-FX)


Prestanda

Maximal dataöverföringshastighet	200 Mbps (Full Duplex Mode)
Maximalt överföringsavstånd	2 km (1.2 mi)
Fibertyp	Multiläge
Våglängd	1310nm
Fiber-driftsläge	Halv/full-duplex
Auto MDIX	Ja

Kontakt(er)

Lokala enhetskontakter	Fiberoptisk SC duplex
	RJ-45

Ström

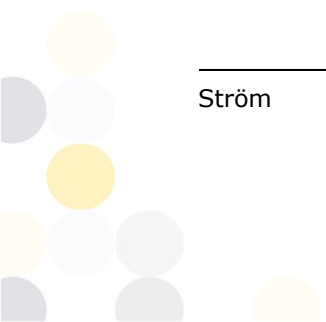

Power Source	AC-adapter medföljer
Inspänning	100 - 240 AC
Inström	0.48A
Utspänning	12V DC
Utström	1.6 A
Polaritet på mittpol	Positiv
Kontakttyp	M

Miljö

Drifttemperatur	0°C to 60°C (32°F to 140°F)
Förvaringstemperatur	-10°C to 70°C (14°F to 158°F)
Luftfuktighet	10~90% RH

Utseende

Färg	Svart
Kabinetttyp	Stål
Produktlängd	6.0 in [15.3 cm]
Produktbredd	3.4 in [87 mm]
Produkthöjd	0.9 in [24 mm]
Produktvikt	13.8 oz [390 g]

Förpackning

Package Length	9.2 in [23.3 cm]
Package Width	7.5 in [19 cm]
Package Height	3.0 in [77 mm]
Fraktvikt (förpackning)	27.5 oz [779 g]

Vad det är i lådan

Ingår i paketet	Fiber Media Converter
-----------------	-----------------------



Universal power adapter: comes ready for NA/EU/UK only when you buy in NA/EU/UK; comes ready for Australia and New Zealand only when you buy in Australia and New Zealand

Grounding Screw

Instruction Manual

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

