


Fiber Optic Cable - Multimode Duplex 62.5/125 - LSZH - LC/MTRJ - 10 m

**Product ID:** FIBLCMT10

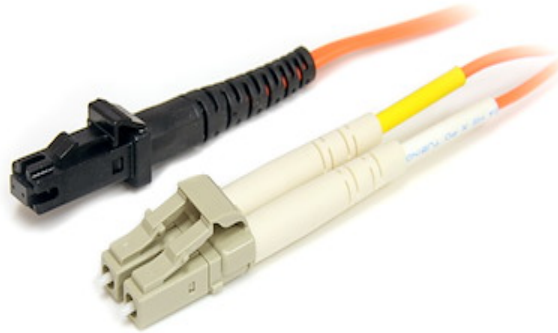

The FIBLCMT10, 10-meter (32.8ft) Multimode 62.5/125 Duplex Fiber Patch Cable is terminated with one LC (male) connector and one MTRJ (male) connector, to provide the necessary connection between fiber networking devices for high-speed, long distance networks.

This LC-MTRJ patch cable is housed in a LSZH (Low-Smoke, Zero-Halogen) flame retardant jacket, to ensure minimal smoke, toxicity and corrosion when exposed to high sources of heat, in the event of a fire. Making it ideal for use in industrial settings, central offices and schools, as well as residential settings where building codes are a consideration.

To ensure optimum performance, our multimode fiber duplex cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Backed by Lifetime Warranty, our LC-MTRJ Multimode Fiber Patch cable is guaranteed to provide long-lasting dependability, and top quality performance.

## Certifications, Reports and Compatibility

### Applications

- Used by long distance networks with mission critical data
- Telecommunication/Data communication
- Broadband systems
- Ideal solution for data applications requiring high speed data transmission

## Features

- Attenuation loss meets or exceeds industry standards
- LSZH (Low-Smoke, Zero-Halogen) cable jacket
- Immune to electrical interference

---

### Hardware

Warranty	Lifetime
Fire Rating	LSZH Rated (Low Smoke Zero Halogen)
Fiber Size	62.5/125

---

### Performance

Fiber Classification	OM1
Type	Multi Mode

---

### Connector(s)

Connector A	Fiber Optic LC Duplex
Connector B	Fiber Optic MT-RJ

---

### Physical Characteristics

Color	Orange
Cable Length	32.8 ft [10 m]
Product Length	32.8 ft [10.0 m]

---

### Packaging Information

Package Length	7.8 in [19.9 cm]
Package Width	0.7 in [18 mm]
Package Height	8.3 in [21.1 cm]
Shipping (Package) Weight	2.5 oz [70 g]

---

*\*Product appearance and specifications are subject to change without notice.*