


Fiber Optic Cable - Multimode Duplex 62.5/125 - LSZH - LC/ST - 10 m

Product ID: FIBLCST10

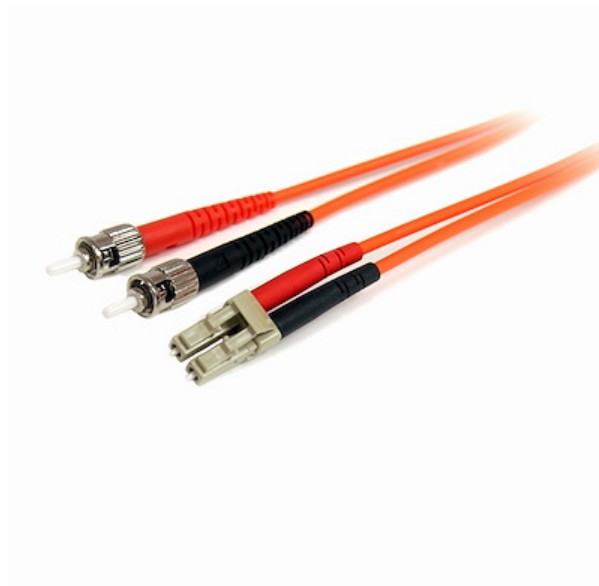

The FIBLCST10 10-meter (32.8ft) Multimode 62.5/125 Duplex Fiber Patch Cable is terminated with one LC (male) connector and one ST (male) connector, to provide the necessary connection between fiber networking devices for high-speed, long distance networks.

This LC-ST patch cable is housed in a LSZH (Low-Smoke, Zero-Halogen) flame retardant jacket, to ensure minimal smoke, toxicity and corrosion when exposed to high sources of heat, in the event of a fire. Making it ideal for use in industrial settings, central offices and schools, as well as residential settings where building codes are a consideration.

To ensure optimum performance, our multimode fiber duplex cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Backed by Lifetime Warranty, our LC-ST Multimode Fiber Patch cable is guaranteed to provide long-lasting dependability, and top quality performance.

Certifications, Reports and Compatibility



Applications

- Used by long distance networks with mission critical data
- Telecommunication/Data communication
- Broadband systems

- Ideal solution for data applications requiring high speed data transmission

Features

- Attenuation loss meets or exceeds industry standards
- LSZH (Low-Smoke, Zero-Halogen) cable jacket
- Immune to electrical interference

Hardware

Warranty	Lifetime
Fire Rating	LSZH Rated (Low Smoke Zero Halogen)
Fiber Size	62.5/125

Performance

Maximum Data Transfer Rate	10Gbps
Cable Rating	1Gbps / 10Gbps
Fiber Classification	OM1
Type	Multi Mode

Connector(s)

Connector A	1 - Fiber Optic LC Duplex
Connector B	1 - Fiber Optic ST Duplex

Environmental

Operating Temperature	-20C to 60C (-4F to 140F)
Storage Temperature	-20C to 60C (-4F to 140F)
Humidity	0~90% RH

Physical Characteristics

Color	Orange
Cable Length	32.8 ft [10 m]
Product Length	32.8 ft [10.0 m]



Product Width 0.0 in [0.0 mm]

Product Height 0.0 in [0.0 mm]

Weight of Product 0.0 oz [0.0 g]

**Packaging
Information**

Package Length 7.8 in [19.9 cm]

Package Width 0.7 in [1.7 cm]

Package Height 8.3 in [21.1 cm]

Shipping (Package)
Weight 2.8 oz [80.0 g]

****Product appearance and specifications are subject to change without notice.***

