


10m Multimode 62.5/125 Duplex Fiber Patch Cable SC-SC

Product ID: FIBSCSC10

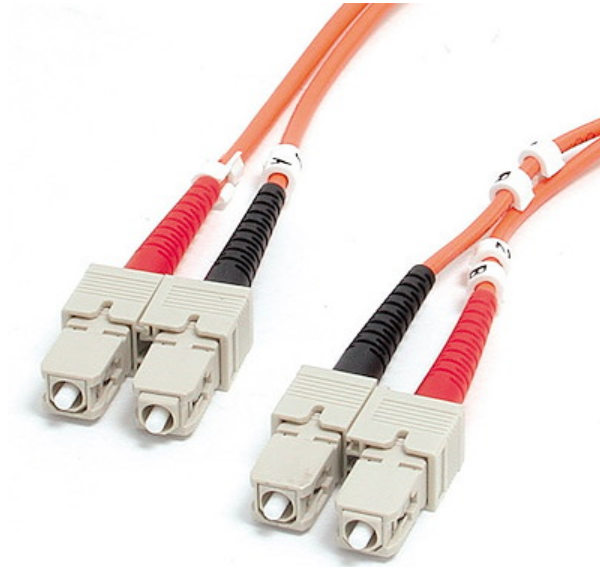

This 10m SC/SC Duplex 62.5/125 Multimode Fiber Patch Cable provides the necessary connection between fiber networking devices for high-speed, long distance networks.

Ensuring optimal data transfers and network stability, 62.5/125-micron cables offer nearly three times the bandwidth of 62.5/125-micron cables, so your data will be transferred at higher rates over longer distances.

Each Duplex 62.5/125 Multimode Fiber Patch Cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Certifications, Reports and Compatibility



Applications

- Used by high-speed, long-distance networks with mission critical data.

Features

- StarTech.com's lifetime warranty on cables
 - All fiber optic cables are individually tested and certified
-

Hardware

Warranty	Lifetime
Fiber Size	62.5/125

Performance

Fiber Classification	OM1
Type	Multi Mode

Connector(s)

Connector A	1 - Fiber Optic SC Duplex
Connector B	1 - Fiber Optic SC Duplex

Physical Characteristics

Color	Orange
Cable Length	32.8 ft [10 m]
Product Length	32.8 ft [10.0 m]
Product Width	0.0 in [0.0 mm]
Product Height	0.0 in [0.0 mm]
Weight of Product	0.0 oz [0.0 g]

Packaging Information

Package Length	7.8 in [19.9 cm]
Package Width	0.8 in [2.1 cm]
Package Height	8.3 in [21.1 cm]
Shipping (Package) Weight	6.4 oz [180.0 g]

What's in the Box

Included in Package	1 - 10 M Multimode Fiber Optic Cable SC-SC
---------------------	--

**Product appearance and specifications are subject to change without notice.*

