


Fiber Optic Cable - Multimode Duplex 62.5/125 - LSZH - SC/SC - 1 m

Productcode: FIBSCSC1

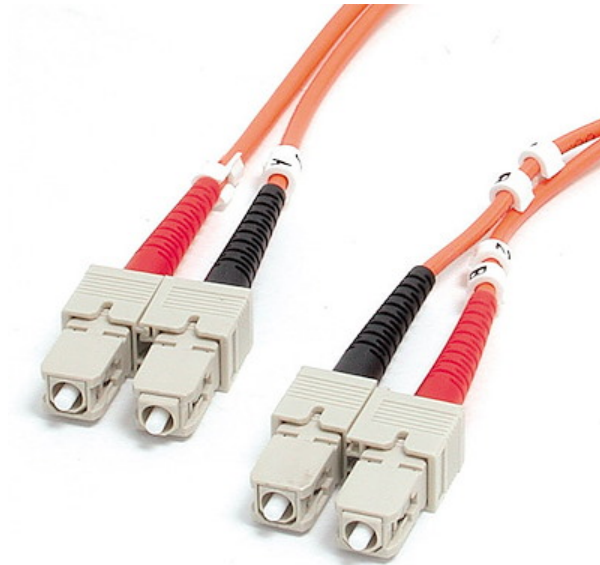

The FIBSCSC1 1-meter (3.3ft) Multimode 62.5/125 Duplex Fiber Patch Cable is terminated at both ends with SC (male) connectors, to provide the necessary connection between fiber networking devices for high-speed, long distance networks.

This SC-SC patch cable is housed in a LSZH (Low-Smoke, Zero-Halogen) flame retardant jacket, to ensure minimal smoke, toxicity and corrosion when exposed to high sources of heat, in the event of a fire. Making it ideal for use in industrial settings, central offices and schools, as well as residential settings where building codes are a consideration.

To ensure optimum performance, our multimode fiber duplex cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Backed by Lifetime Warranty, our SC-SC Multimode Fiber Patch cable is guaranteed to provide long-lasting dependability, and top quality performance.

## Certificaties, rapporten en compatibiliteit

### Toepassingen

- Used by long distance networks with mission critical data
- Telecommunication/Data communication
- Broadband systems
- Ideal solution for data applications requiring high speed data transmission

## Eigenschappen

- Attenuation loss meets or exceeds industry standards
- LSZH (Low-Smoke, Zero-Halogen) cable jacket
- Immune to electrical interference

---

### Hardware

Garantiebeleid	Lifetime
Brandbestendigheid	LSZH-rating (weinig rook, geen halogeen)
Glasvezelformaat	62.5/125

---

### Prestaties

Maximale overdrachtsnelheid	10 Gbit/s
Kabelspecificatie	1Gbps / 10Gbps
Glasvezelclassificatie	OM1
Glasvezeltype	Multi-Mode

---

### Connector(en)

Connector A	Glasvezel SC duplex
Connector B	Glasvezel SC duplex

---

### Gebruiksomgeving

Bedrijfstemperatuur	-20°C to 60°C (-4°F to 140°F)
Opslagtemperatuur	-20°C to 60°C (-4°F to 140°F)
Vochtigheid	0% - 90% rel. luchtvochtigheid

---

### Fysieke eigenschappen

Kleur	Oranje
Kabellengte	39.4 in [100 cm]



Lengte product	39.4 in [100.0 cm]
Breedte product	0.0 in [0.0 mm]
Hoogte product	0.0 in [0.0 mm]
Gewicht product	1.1 oz [31.0 g]

---

Verpakkingsinformatie

Package Length	8.7 in [22.0 cm]
Package Width	7.9 in [20.0 cm]
Package Height	1.1 in [27.0 mm]
Verzendgewicht (verpakt)	1.4 oz [40.0 g]

---

Wat wordt er meegeleverd

Meegeleverd	1 M Multimode Fiber Optic Cable SC-SC
-------------	---------------------------------------

---

\* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.

