


40m Multimode 62.5/125 Duplex Fiber Patch Cable SC-SC

Product ID: FIBSCSC40

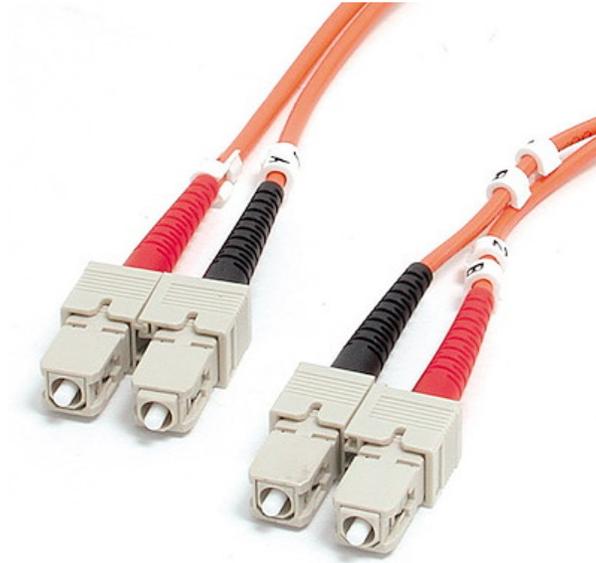

This 62.5/125 micron Duplex Fiber Optic Patch Cable is terminated with SC (male) connectors to provide the necessary interconnect between fiber networking devices for high-speed, long distance networks.

Each Duplex Fiber Optic Patch Cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Certifications, Reports and Compatibility



Applications

- Used by high-speed, long-distance networks with mission critical data.

Features

- StarTech.com's lifetime warranty on cables
- All fiber optic cables are individually tested and certified

Hardware

Warranty

Lifetime

Fiber Size 62.5/125

Fiber Classification OM1

Performance

Type Multi Mode

Connector(s)

Connector A 1 - Fiber Optic SC Duplex

Connector B 1 - Fiber Optic SC Duplex

Physical Characteristics

Color Orange

Cable Length 131.2 ft [40 m]

Product Length 131.2 ft [40.0 m]

Packaging Information

Package Length 9.8 in [25 cm]

Package Width 1.6 in [40 mm]

Package Height 12.6 in [32 cm]

Shipping (Package) Weight 1.4 lb [0.6 kg]

What's in the Box

Included in Package 1 - 40m MMode Duplex Fiber Optic Cable SC-SC

Warranty Information

Warranty Lifetime

**Product appearance and specifications are subject to change without notice.*