

## Ceiling TV Mount - 3.5' to 5' Pole

**Product ID:** FLATPNLCEIL



This ceiling TV mount supports VESA mount compatible TVs from 32" to 75" in size, with a weight capacity of up to 110 lb. (50 kg). It lets you save wall and floor space by hanging your flat-panel LCD, LED or plasma TV from the ceiling in a prominent area.

The ceiling mount is ideal for use in corporate boardrooms, lobbies, entrances, restaurants, bars and meeting places.

With a telescopic pole, the TV mount lets you suspend a display at your desired distance from the ceiling. This works well with a range of ceiling heights. The steel pole can extend from 42" to 61" (1060 to 1560 mm) , with a total lift (height extension) of 19.7" (500 mm).

The flat-screen ceiling mount accommodates a wide variety of ceiling types. You can swivel the TV to work with virtually any type of ceiling for level viewing, including sloped ceilings (up to 60 degrees), and pitched or horizontal (flat) ceilings.

You can adjust your TV to create a comfortable viewing angle, by tilting it up to -25 degrees down towards your audience for optimum visibility. Plus, the full-motion mount lets you swivel your display around the pole + 180 / - 180 degrees, without using tools.

Simply attach the included vertical brackets, with built-in hooks, to the back of your TV. Once attached, hang your TV securely onto the ceiling mount. The +/-3 degree post-installation leveling adjustments ensure ideal positioning after hanging.

FLATPNLCEIL is backed by a StarTech.com 5-year warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

## Applications

- Suspend a flat-screen TV from the ceiling for easy viewing
- Ideal for boardrooms, lobbies, entrances, meeting spaces, classrooms
- Keep your guests informed and entertained

## Features

- Save space by suspending your 32 to 75" flat-screen TV from the ceiling
- Min-max pole length extension of 42" to 61" (1060 to 1560 mm)
- Durable steel mount supports TVs up to 110 lb. (50 kg)
- Ceiling TV mount swivels +60 /-60 degrees to adjust to sloped or level ceilings
- Full-motion mount lets you swivel the display +180 /-180 degrees around the pole and tilt downwards -25 degrees, without using tools
- Easy setup, with a hook-and-mount design

---

## Hardware

Warranty	5 Years
Wallmountable	No
Cable Management	Yes
# of Displays Supported	1
Mounting Options	Ceiling Mount
VESA Hole Pattern(s)	200x200 mm
	300x300 mm
	400x200 mm
	400x400 mm
	600x400 mm

---

## Performance

General Specifications	Post-Installation Leveling Adjustment: +/-3
Weight Capacity (Per Display)	110.5 lb [50 kg]
Minimum Display Size	32"



Maximum Display Size	75"
Fits Curved Display	Yes
Video Wall	No
Height Adjustment	Yes
Minimum Height	3.5 ft [1.1 m]
Maximum Height	5.1 ft [1.6 m]
Display Tilt	+0 / -25
Swivel / Pivot	+180 to -180
Display Rotation	360
Anti-theft	No

---

#### Physical Characteristics

Color	Black
Material	Steel
Product Length	26.8 in [68.0 cm]
Product Width	5.5 in [14.0 cm]
Product Height	5.8 ft [1.8 m]
Weight of Product	13.2 lb [6.0 kg]

---


#### Packaging Information

Package Length	37.1 in [94.2 cm]
Package Width	12.3 in [31.2 cm]
Package Height	5.7 in [14.6 cm]
Shipping (Package) Weight	17.3 lb [7.8 kg]

---

#### What's in the Box

Included in Package	ceiling mount and pole
---------------------	------------------------

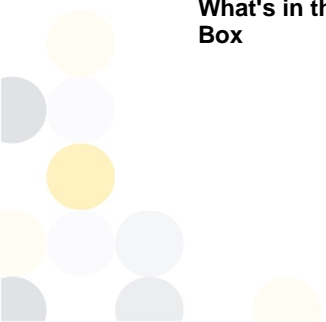

extension pole

vertical brackets

horizontal bracket

bolts

nuts

M13 wrench

M5 Allen key

mounting template

M5x14 mm screws

M6x14 mm screws

M8x30 mm screws

M6x30 mm screws

M8x50 mm screws

washers

short spacers

long spacers

6.3x55 mm screws

concrete anchors

flat washers

instruction manual

---

***\*Product appearance and specifications are subject to change without notice.***

