


TV Wall Mount supports up to 70 inch VESA Displays - Low Profile Full Motion Universal TV Flat Screen Wall Mount - Heavy Duty Adjustable Tilt/Swivel Articulating Arm Bracket

Product ID: FPWARTB2

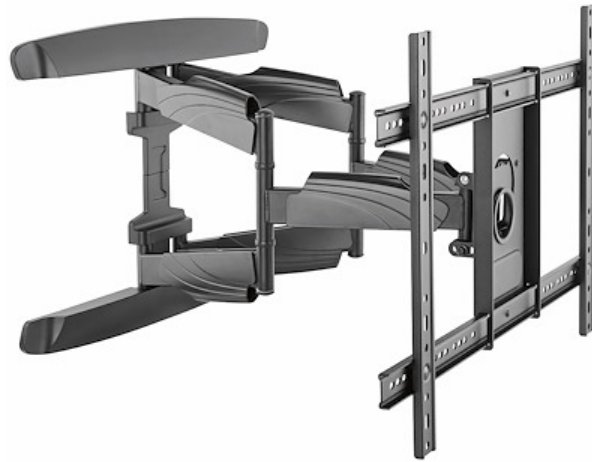

Maximize space while creating an impressive display. This full-motion TV wall mount supports flat-screen TVs from 32" to 70" in size, with a weight capacity of 99 lb. (45 kg).

Mount your flat-screen TV in a location that's convenient for visitors, clients and employees, and free up valuable space. The wall mount is ideal for a lobby, boardroom or other venue. The TV wall mount also includes built-in cable management to keep cables neatly out of sight.

The TV wall mount features dual arms that extend out to 20.4" (517 mm) from the wall to provide a wide range of movement and accommodate different screen positions and angles. The arms can also fold to tuck in closely to the wall, providing a low profile that enables your display to be positioned just 2.24" (57 mm) from the wall.

You can swivel your display +90° / -90 degrees and tilt +5° / -8 degrees, letting you angle your TV display toward your audience. Plus, the tilt feature lets you adjust the TV so that you can view it comfortably at any height. A built-in level adjustment also offers 5 degree clockwise and counterclockwise turning, to ensure your display is perfectly level.

The heavy-duty steel construction, dual-arm design and dual-stud mounting for studs placed 16" apart, provides increased durability and security. It safely and securely supports your flat-screen TV, to protect your investment.

FPWARTB2 is backed by a StarTech.com 5-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility



Applications

- Wall-mount your flat-screen TV for optimal viewing
- Ideal for lobbies, boardrooms, meeting spaces and classrooms
- Keep your guests informed and entertained

Features

- **LARGE 70" TV WALL MOUNT:** This heavy-duty TV wall mount supports VESA compatible displays (incl. curved TVs) up to 70 inch (99 lb/45 kg) w/ a durable full-motion steel frame and a powder-coated finish
- **WIDE RANGE OF MOTION:** Articulating & adjustable TV wall mount offers +/-90 swivel, +2/-15 tilt & +/-5 LCD screen level adjustment without the use of additional tools to ensure display is level
- **EXTENDING ARMS:** Arms extend from 2.4" (57mm) to 20.4" (517mm) from the wall; With the length of the arms, center of the television display has an overall lateral range (left to right) of 34.6" (880mm)
- **COMPATIBILITY:** Universal TV wall mount supports LG, Samsung, Sony, Sharp, and others (screws/spacers incl) & VESA hole patterns 200x100, 200x200, 200x300, 200x400, 300x200, 300x300, 400x200, 400x300, 400x400, 600x200, 600x300, 600x400
- **TIDY AESTHETIC:** The flat panel TV wall mounting bracket w/ integrated cable management & optional black snap-on covers keeps cables organized; ideal for customer-facing digital signage

Hardware

Warranty	5 Years
Wallmountable	Yes
Cable Management	Yes
Articulating	Yes
# of Displays Supported	1
Mounting Options	Wall-Mount
Minimum Profile from Wall	2.2 in [57 mm]
VESA Hole Pattern(s)	200x100 mm
	200x200 mm
	200x300 mm
	200x400 mm
	300x200 mm

300x300 mm

400x200 mm

400x300 mm

400x400 mm

600X200 mm

600x300 mm

600x400 mm

Performance

Weight Capacity (Per Display)	99.2 lb [45 kg]
Minimum Display Size	32"
Maximum Display Size	70"
Fits Curved Display	Yes
Video Wall	No
Maximum Arm Extension	20.4 in [517.5 mm]
Display Tilt	+5 / -8
Swivel / Pivot	+90 / -90
Anti-theft	No

Physical Characteristics

Color	Black
Material	Steel
Product Length	25.3 in [64.3 cm]
Product Width	20.4 in [51.7 cm]
Product Height	16.5 in [41.8 cm]
Weight of Product	14.9 lb [6.8 kg]

Packaging Information

Package Quantity	1
Package Length	16.5 in [41.8 cm]
Package Width	26.6 in [67.6 cm]
Package Height	3.1 in [7.8 cm]
Shipping (Package) Weight	16.2 lb [7.3 kg]

What's in the Box

Included in Package	1 - wall mount
	2 - vertical brackets
	2 - horizontal brackets
	1 - wrench
	4 - bracket screws
	4 - nuts
	2 - mounting screws
	4 - M5x14 mm screws
	4 - M6x14 mm screws
	4 - M6x30 mm screws
	4 - M8x30 mm screws
	4 - M8x50 mm screws
	4 - small washers
	4 - large washers
	8 - small spacers
	8 - large spacers
	6 - screws
	6 - concrete screws
	6 - bracket washers

1 - instruction manual

**Warranty
Information**

Warranty

5 Years

****Product appearance and specifications are subject to change without notice.***