


Desk Mount For 2x Vertically Stacked Monitors, Dual 49", Total 70lb (32kg), C-Clamp, Quick-Release VESA System, Widescreen 16:9/Ultrawide 32:9, TAA

Product ID: H2MPV-MONITOR-MOUNT

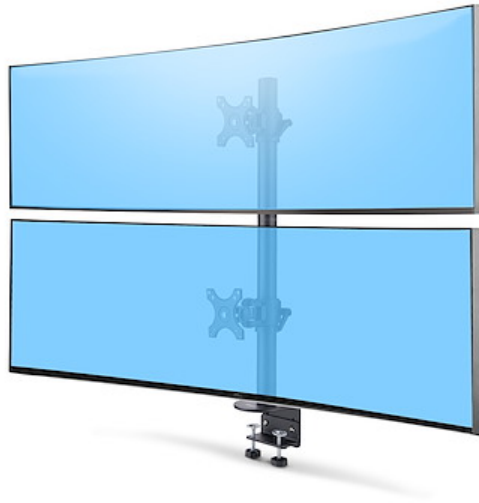

This dual ultrawide display monitor mount is engineered to support up to two vertically stacked 49-inch 32:9 aspect ratio curved screens, providing an enhanced workspace for data aggregation and multi-window applications. The monitor desk mount is TAA-compliant.

With a total weight capacity of 35.3lb (16kg) per VESA mount, the vertically stacked mount provides a secure and stable solution for mounting heavy monitors whether they are standard (4:3), widescreen (16:9), and ultrawide (32:9).

Fixed C-clamp design fits desks ranging from 1 to 3.9 inches (2.5 to 10cm) thick.

The double monitor mount features concealed cable management running the cables inside the pole for an organized and clutter-free setup. The powder-coated finish enhances durability and aesthetics.

Detachable VESA plates feature a toolless quick-release mechanism, simplifying display installation and removal. The mount supports VESA 75x75mm and 100x100mm standards, making it compatible with a wide range of monitors.

The mount's adjustable design enables height adjustments along the 27.4-inch (69.6cm) pole. Each monitor can be tilted and swiveled up to +/-90 and rotated 360 for seamless switching between portrait and landscape orientations. Additionally, the monitor mounts can be rotated around the pole without requiring tools, offering maximum flexibility.

Certifications, Reports and Compatibility

Applications

Features

- **DUAL ULTRAWIDE DISPLAY SUPPORT:** This monitor mount is designed to hold up to two vertically stacked 49" 32:9 aspect ratio curved screens, maximizing workspace & enhancing productivity; Ideal for data aggregation & multi-window applications; TAA-compliant
- **70LB (32KG) TOTAL WEIGHT CAPACITY:** Supports up to 35.3lb (16kg) per VESA mount, ensuring a stable and safe mounting solution for stacking even the heaviest monitors; Robust design makes it ideal for both standard, widescreen, and ultrawide monitors
- **CONCEALED CABLE MANAGEMENT:** Double monitor mount features a concealed cable management system to keep the workspace tidy and organized, hiding cables inside the 2in (5cm) pole for a clean look; Powder coated finish for enhanced durability
- **QUICK-RELEASE VESA MOUNT:** Toolless, detachable VESA plates with quick-release mechanism for easy display installation & removal; Meets VESA 75x75mm and 100x100mm; Fixed C-clamp design is compatible with desks from 1 to 3.9-inch (2.5 to 10cm) in thickness
- **ADJUSTABLE DESIGN:** Features easy height adjustments along the 27.4in (69.6cm) pole; Monitors can be tilted and swiveled +/-90 deg and rotated 360 deg for portrait/landscape viewing; Monitor mounts can be rotated around the pole without the need for tools

Hardware

Warranty	5 Years
Wallmountable	No
Cable Management	Yes
Tools Included	Yes
Articulating	No
# of Displays Supported	2
Mounting Options	Desk Clamp
VESA Hole Pattern(s)	75x75 mm 100x100 mm
Mounting Surface Thickness	C-Clamp 1-4in (25-100mm) ,

Performance

Weight Capacity (Per Display)	28.7 lb [13 kg]
Minimum Display Size	17"

Maximum Display Size	49" (32:9)
Fits Curved Display	Yes
Fits UltraWide Displays	Yes
Height Adjustment	Yes
Maximum Height	27.4 in [696 mm]
Display Tilt	+/- 90
Display Swivel	+90 / - 90
Display Rotation	+180 / -180

Physical Characteristics

Color	Black
Construction Material	Steel and Plastic
Product Length	8.4 in [21.4 cm]
Product Width	36.3 in [92.2 cm]
Product Height	36.3 in [92.2 cm]
Weight of Product	15.4 lb [7.0 kg]

Packaging Information

Package Length	8.4 in [21.3 cm]
Package Width	32.9 in [83.5 cm]
Package Height	6.3 in [16.0 cm]
Shipping (Package) Weight	16.1 lb [7.3 kg]

What's in the Box

Included in Package	1 - Desk Clamp, Lower
	1 - Pole Assembly
	1 - Pole Cap
	2 - VESA Mount

2 - VESA Plate

2 - Support Collar

8 - M4x10mm Screws

8 - M4x16mm Screws

8 - 3/8"x1/2" Screws

8 - Spacers

1 - M6 Hex Key

1 - M3 Hex Key

1 - Wrench

1 - Quick-Start Guide

**Warranty
Information**

Warranty

5 Years

****Product appearance and specifications are subject to change without notice.***