

15ft (4.5m) Heavy Duty Extension Cord, NEMA 5-15R to NEMA 5-15P Black Extension Cord, 15A 125V, 14AWG, Heavy Gauge Extension Power Cable, NEMA 5-15R to NEMA 5-15P AC Power Cord

Produkt-ID: HX-15F-POWER-CORD




The HX-15F-POWER-CORD is a NEMA 5-15P to NEMA 5-15R power extension cable which features heavy gauge wire (14 AWG) that is suitable for handling 125V at 15A, making it a reliable solution for connecting larger servers to PDUs (Power Distribution Units).

This 15ft power extension cable extends your existing power connection, enabling the use of a PC or powered device.

HX-15F-POWER-CORD is backed for life, including free lifetime 24/5 multi-lingual technical assistance.

Zertifikate Berichte und Kompatibilität

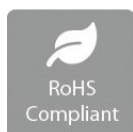

Anwendungen

Merkmale

- **HEAVY DUTY EXTENSION CABLE:** This 15ft (4.5m) 14AWG universal power cord with NEMA 5-15P and NEMA 5-15R connectors is suitable for workstations/home offices | Indoor use only | Rated to carry 125V at 15A

- **PERFORMANCE AND SAFETY:** UL listed components | Fully molded strain relief on connectors for durability | Fire Rating: VW-1 | 3 Conductor Power Cable with 100% copper wire | Available in 6ft and 10ft
- **SPECS:** 15ft (4.5m) AC Power Cord | NEMA 5-15P to NEMA 5-15R | 14AWG | 125V 15A (Max) | Jacket Type: SJT | Jacket Material: PVC | Color: Black | Temperature Range: 14 to 95°F (-10 to 35°C) | Cable Outer Diameter: 0.36in (9.25mm)
- **COMPATIBILITY:** NEMA 5-15 PC Power Cord works with 3 prong North American plugs and receptacles | Extend power connections to servers, desktop computers, monitors, printers, and more | Replacement power extension cable/cord
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this power extension cable is backed for life, including free lifetime 24/5 multi-lingual technical assistance

Hardware

Garantiebestimmungen	Lifetime
Anzahl von Leitern	3
Steckverbinderplatten	Nickel
Typ der Kabelummantelung	PVC - Polyvinyl Chloride
Feuerwiderstandssklasse	Klasse VW-1e
Kabeltyp	SJT

Steckverbinder

Steckverbinder A	1 - NEMA 5-15 Strom (Nordamerika)
Steckverbinder B	1 - NEMA 5-15 Strom (Nordamerika)

Strom

Eingangsspannung	125 AC
Eingangsstrom	15 A

Umgebungsbedingungen

Betriebstemperatur	-10 to 35°C (14 to 95°F)
Lagertemperatur	-15 to 70°C (5 to 158°F)

	Feuchtigkeit	5 % ~ 95 %
Physische Eigenschaften	Farbe	Schwarz
	Kabellänge	15.0 ft [4.6 m]
	Außendurchmesser des Kabels	0.4 in [9.2 mm]
	Produktlänge	1.0 in [2.5 cm]
	Produktbreite	180.1 in [457.5 cm]
	Produkthöhe	1.4 in [3.5 cm]
	Produktgewicht	1.5 lb [0.7 kg]
Verpackungsinformationen	Paketmenge	1
	Paketlänge	9.1 in [23.0 cm]
	Paketbreite	4.3 in [10.9 cm]
	Pakethöhe	2.6 in [6.7 cm]
	Versandgewicht (Verpackung)	1.5 lb [0.7 kg]
Verpackungsinhalt		
	Im Paket enthalten	1 - Netzkabelverlängerung
Garantieinformationen		
	Warranty	Lifetime

* Größe, Aussehen und Spezifikationen sind Änderungen ohne vorherige Ankündigung vorbehalten.