

2 Port Industrial USB to Serial RJ45 Adapter - Wallmount and DIN Rail

Produkt ID: ICUSB2322RJ




The ICUSB2322RJ 2-Port Industrial USB to Serial RJ45 Adapter (Wallmount and DIN Rail) allows you to add two RS232 serial connections using RJ45 signaling ports to a PC or Server through a single USB 2.0 port.

The RS232 to RJ45 adapter features COM port retention to maintain your port number assignments across a reboot and supports serial data rates up to 921 Kbps. The included DIN Rail clips (Top Hat) and wall-mounting brackets provide simple solutions for out of the way installations, while the sturdy metal enclosure offers durability in harsh industrial environments.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

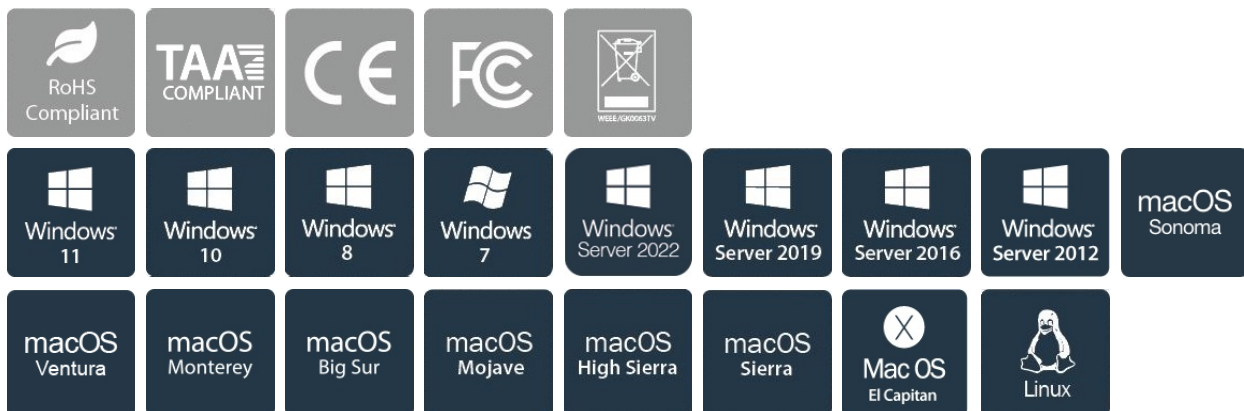

Användning

- Perfect for IT Administrators looking to add legacy functionality to newer laptops, PCs and servers that lack integrated RS232
- Connect, monitor and control industrial/automotive sensors and equipment

Funktioner

- Adds 2 RS232 serial RJ45 connectors via a single USB port
- Includes wallmount and Top-Hat DIN rail mounting brackets
- Supports data rates up to 921.6 Kbps
- COM Port retention
- USB-Powered - No external adapter required
- USB 2.0 High Speed (480Mbps) and Full Speed (12Mbps) supported
- USB connection features optional latching female screw holes for added security

Hårdvara

Garantipolicy	2 Years
Portar	2
Gränssnitt	Seriell
Busstyp	USB 2.0
Porttyp	Extern hubb
Chipset-ID	FTDI - FT232R

Prestanda

Seriellt protokoll	RS-232
Maximal överföringshastighet	921,6 kbps
Databitar	7, 8
FIFO	128 Bytes
Paritet	Odd, Even, Mark, Space, None

	Stoppbitar	1, 2
Kontakt(er)	Kontakttyp(er)	2 - RJ-45
		1 - USB B (4-stifts)
Mjukvara	OS-kompatibilitet	Windows® CE (4.2, 5.0, 6.0), XP Embedded, 98SE, 2000, XP, Vista, 7, 8, 8.1, 10, 11
		Windows Server® 2003, 2008 R2, 2012, 2012 R2, 2016, 2019, 2022
		macOS 10.6 till 10.14, 11.0, 12.0, 13.0, 14.0, 15.0, 26.1
		Linux 2.4.x till 4.11.x Endast LTS-versioner
Ström	Strömkälla	Strömförsörjd via USB
Miljö	Drifttemperatur	0°C to 55°C (32°F to 131°F)
	Förvaringstemperatur	-20°C to 85°C (-4°F to 185°F)
	Luftfuktighet	5~95% RH
Utseende	Färg	Svart
	Kabinetttyp	Stål
	Produktlängd	2.6 in [65 mm]
	Produktbredd	1.7 in [4.2 cm]
	Produkthöjd	0.8 in [2 cm]
	Produktvikt	2.8 oz [78 g]
Förpackning	Förpackningsantal	1

Paketets längd	8.3 in [21.1 cm]
Paketets bredd	5.7 in [14.4 cm]
Paketets höjd	1.6 in [41 mm]
Fraktvikt (förpackning)	0.6 lb [0.3 kg]

Vad det är i lådan

Ingår i paketet	1 - 2 Port USB to Serial RJ45 Adapter
	2 - DIN Rail Clips
	1 - Wallmount Bracket
	1 - USB A to B Cable
	1 - Driver CD
	1 - Instruction Manual

Warranty
Information

Warranty	2 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.