


24in Internal USB Motherboard Header to Serial RS232 Adapter - TAA

Produkt ID: ICUSB232INT1

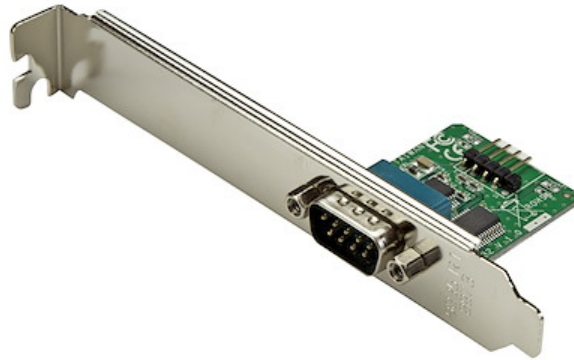

The ICUSB232INT1 USB to RS232 Serial Adapter lets you add an RS232 port to any desktop system that is equipped with an available USB motherboard header.

Unlike standard USB to serial cables, this cable is designed for use inside the PC case, affording an entirely internal solution with no mess or extra adapters needed.

This compact and simple USB adapter offers a cost-effective solution that bridges the compatibility gap between modern computers and legacy serial peripherals.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet



Användning

- Perfect for system builders looking to add legacy functionality to newer motherboards that lack an integrated RS232 port
- Connect, monitor and control industrial/automotive sensors and equipment
- Connect bar code scanners, receipt printers and other serial devices to an internal USB motherboard header
- Connect a satellite receiver, serial modem, or PDA with serial sync
- Connect and program LED and Digital signage boards with serial communication ports

Funktioner

- USB Header to Straight-Through RS232 Serial
- Bus-Powered – no separate power supply or battery required
- Supports COM port retention
- Single chip USB to asynchronous serial data transfer interface
- UHCI/OHCI/EHCI host controller compatible
- USB 2.0 Full Speed compatible
- Synchronous and asynchronous bit bang interface options with RD# and WR# strobes
- FIFO receive and transmit buffers for high data throughput.

Hårdvara

Garantipolicy	2 Years
Portar	1
Gränssnitt	Seriell
Busstyp	Moderkortskontakt
Korttyp	Standardprofil (inkl. LP-fäste)
Porttyp	Inbyggd på kort
Chipset-ID	FTDI - FT232RL

Prestanda

	Seriellt protokoll	RS-232
	Maximal överföringshastighet	115.2 kbps
	Databitar	7, 8
	FIFO	256 Bytes
	Paritet	None, Odd, Even, Space, Mark
	Stoppbitar	1, 2
Kontakt(er)	Interna portar	1 - IDC (10-stifts, moderkortskontakt)
	Externa portar	1 - DB-9 (9-stifts, D-Sub)
Mjukvara	OS-kompatibilitet	Windows® CE (4.2, 5.0, 6.0), XP Embedded, 98SE, 2000, XP, Vista, 7, 8, 8.1, 10, 11, 11 ARM Windows Server® 2003, 2008 R2, 2012, 2012 R2, 2016, 2019, 2022 macOS 10.6 to 10.15, 11.0, 12.0, 13.0, 14.0, 15.0 Linux Kernel 3.0.x and up - LTS Versions only
	Microsoft WHQL-certifierad	Ja
Miljö	Drifttemperatur	-10°C to 80°C (14°F to 176°F)
	Förvaringstemperatur	-20°C to 100°C (-4°F to 212°F)
	Luftfuktighet	5~85% RH
Utseende	Färg	Grön
	Kabinetttyp	Stål
	Kabellängd	2.0 ft [0.6 m]
	Produktlängd	1.8 in [45 mm]

Produktbredd	4.8 in [12.3 cm]
Produkthöjd	0.5 in [1.2 cm]
Produktvikt	1.1 oz [31 g]

Förpackning

Förpackningsantal	1
Paketets längd	5.6 in [14.3 cm]
Paketets bredd	6.9 in [17.5 cm]
Paketets höjd	1.3 in [3.3 cm]
Fraktvikt (förpackning)	4.3 oz [122.0 g]

Vad det är i lådan

Ingår i paketet	1 - USB to RS232 Serial Adapter
	1 - Low profile bracket
	1 - Driver CD
	1 - Instruction Manual

Warranty Information

Warranty	2 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.