

6 ft. (1.8 m) Cisco USB Console Cable - USB to RJ45

Product ID: ICUSBROLLOVR




This Cisco USB console cable offers a reliable connection from your desktop or laptop to networking equipment that features a console port.

Create a direct connection from the USB 2.0 port on your computer or laptop to the RJ45 console port on your router, server, firewall or switch. This Cisco rollover cable is compatible with most routers, including Cisco, Juniper, Ubiquiti or TP-Link, providing an easy connection for programming your networking equipment from your Windows, Mac or Linux computer.

Expertly designed and constructed with only the highest quality materials, this USB to Ethernet cable provides maximum dependability, supporting data transfer rates up to 460Kbps. It also provides a reliable and hassle-free connection without the need for additional adapters or external power.

ICUSBROLLOVR is backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

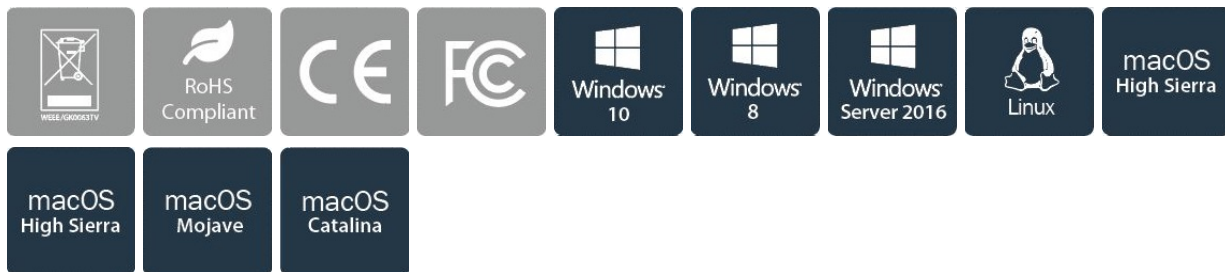

Applications

- Connect a computer terminal to a router console port
- Configure your networking equipment through the USB port on your laptop or desktop computer
- Connect laptops to compatible routers, servers or firewalls

Features

- Directly connect a USB-equipped laptop or desktop to a router console, without the need for an adapter
- Supports connections to network devices that feature a console port
- Maximum compatibility with Cisco, Juniper, Ubiquiti or TP-Link routers
- Supports a direct USB console connection, with no additional adapters
- Constructed of high-quality materials, supports transfer rates of up to 460Kbps

Hardware	Warranty	2 Years
	Ports	1
	Cable Jacket Material	PVC - Polyvinyl Chloride
	Bus Type	USB 2.0
	Port Style	Cable Adapters
	Industry Standards	USB 1.1/2.0, RS-232
	Chipset ID	Prolific PL2303HXD
Performance	Max Baud Rate	460.8 Kbps
	Data Bits	5, 6, 7, 8
	FIFO	512 Bytes
	Parity	Odd, Even, Mark, Space, or None
	Stop Bits	1, 1.5, 2
	Supported Protocols	RS-232
Connector(s)	Connector A	USB Type-A (4 pin) USB 2.0
	Connector B	RJ-45
Software	OS Compatibility	Windows 7, 8, 8.1, 10
		Windows Server 2008 R2, 2012, 2012 R2, 2016
		Mac OS 10.6 to 10.15
		Linux 2.4.31 to 4.11.x <i>LTS version only</i>
Special Notes / Requirements	System and Cable Requirements	One available USB 1.1 (or above) port
Power	Power Source	Bus Powered
Environmental	Operating Temperature	0C to 70C (32F to 158F)

Storage Temperature -20C to 80C (-4F to 176F)

Humidity 20~80% RH

Physical Characteristics

Color	Black
Wire Gauge	28 AWG
Material	Plastic
Cable Length	6.0 ft [1.8 m]
Product Length	6.0 ft [1.8 m]
Product Width	0.9 in [23.400 mm]
Product Height	0.4 in [10.900 mm]
Weight of Product	1.4 oz [40.000 g]

Packaging Information

Package Length	6.7 in [1.7 cm]
Package Width	5.6 in [1.4 cm]
Package Height	1.2 in [30.000 mm]
Shipping (Package) Weight	3.5 oz [98.000 g]

What's in the Box

Included in Package	USB to RJ45 Rollover Cable
Included in Package	Quick-Start Guide

**Product appearance and specifications are subject to change without notice.*

