

6 ft. (1.8 m) Cisco USB Console Cable - USB to RJ45

**Product ID:** ICUSBROLLOVR




This Cisco USB console cable offers a reliable connection from your desktop or laptop to networking equipment that features a console port.

Create a direct connection from the USB 2.0 port on your computer or laptop to the RJ45 console port on your router, server, firewall or switch. This Cisco rollover cable is compatible with most routers, including Cisco, Juniper, Ubiquiti or TP-Link, providing an easy connection for programming your networking equipment from your Windows, Mac or Linux computer.

Expertly designed and constructed with only the highest quality materials, this USB to Ethernet cable provides maximum dependability, supporting data transfer rates up to 460Kbps. It also provides a reliable and hassle-free connection without the need for additional adapters or external power.

ICUSBROLLOVR is backed by a StarTech.com 2-year warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

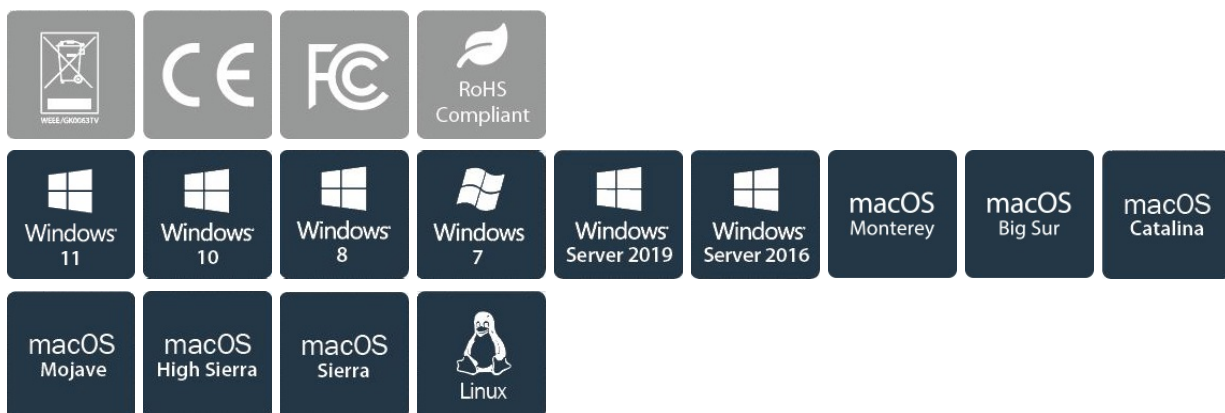

## Applications

- Connect a computer terminal to a router console port
- Configure your networking equipment through the USB port on your laptop or desktop computer
- Connect laptops to compatible routers, servers or firewalls

## Features

- Directly connect a USB-equipped laptop or desktop to a router console, without the need for an adapter
- Supports connections to network devices that feature a console port
- Maximum compatibility with Cisco, Juniper, Ubiquiti or TP-Link routers
- Supports a direct USB console connection, with no additional adapters
- Constructed of high-quality materials, supports transfer rates of up to 460Kbps

---

### Hardware

Warranty	2 Years
Ports	1
Cable Jacket Material	PVC - Polyvinyl Chloride
Bus Type	USB 2.0
Port Style	Cable Adapters
Industry Standards	USB 1.1/2.0, RS-232
Chipset ID	Prolific - PL2303GC

---

### Performance

Max Baud Rate	460.8 Kbps
Data Bits	5, 6, 7, 8
FIFO	512 Bytes
Parity	Odd, Even, Mark, Space, or None
Stop Bits	1, 1.5, 2
Supported Protocols	RS-232

---

**Connector(s)**

Connector A	1 - USB 2.0 Type-A (4 pin, 480Mbps)
Connector B	1 - RJ-45

---

**Software**

OS Compatibility	Windows 7, 8, 8.1, 10, 11 Windows Server 2008 R2, 2012, 2012 R2, 2016, 2019, 2022 macOS 10.6 to 10.15, 11.0, 12.0, 13.0 Linux 2.4.31 and up - <i>LTS Versions only</i>
------------------	---

---

**Special Notes / Requirements**

System and Cable Requirements	One available USB 1.1 (or above) port
-------------------------------	---------------------------------------

---

**Power**

Power Source	Bus Powered
--------------	-------------

---

**Environmental**

Operating Temperature	0C to 70C (32F to 158F)
Storage Temperature	-20C to 80C (-4F to 176F)
Humidity	20~80% RH

---

**Physical Characteristics**

Color	Black
Wire Gauge	28 AWG
Material	Plastic
Cable Length	6.0 ft [1.8 m]
Product Length	6.0 ft [1.8 m]
Product Width	0.9 in [23.4 mm]
Product Height	0.4 in [1.1 cm]
Weight of Product	1.4 oz [40.0 g]

---

**Packaging  
Information**

Package Quantity	1
Package Length	6.7 in [17.0 cm]
Package Width	5.6 in [14.2 cm]
Package Height	1.2 in [30.0 mm]
Shipping (Package) Weight	3.5 oz [98.0 g]

---

**What's in the Box**

Included in Package	1 - USB to RJ45 Rollover Cable
	1 - Quick-Start Guide

---

***\*Product appearance and specifications are subject to change without notice.***