


3m Cat5e RJ45 UTP Netzwerkkabel / Patchkabel - Grau

Produkt-ID: M45PATCH10GR

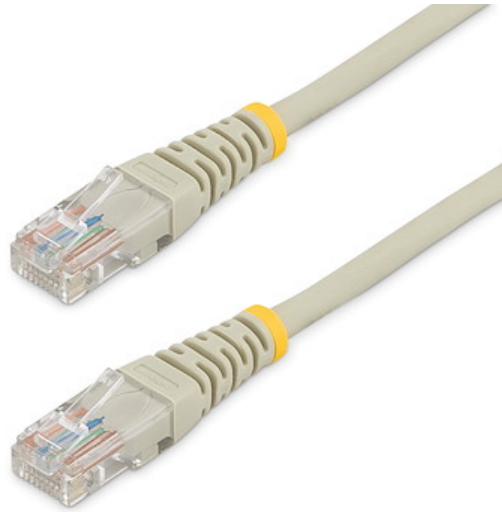

The M45PAT10GR Cat5e Patch Cable (10 ft) meets or exceeds all Cat 5e specifications to ensure reliable Ethernet network connections, and features a durable gray PVC jacket that enables you to color code your network cable runs as needed.

To ensure long-lasting performance, this high quality Cat5e patch cable features molded PVC strain relief that prevents the RJ45 connector termination points from bending at sharp angles - reducing the risk of cable damage, which could decrease network performance.

Constructed of only top quality materials, this Cat5e Patch Cord delivers reliable performance and is backed by our Lifetime Warranty.

StarTech.com Cat5e cables are manufactured using high-quality copper conductors. While many cable manufacturers offer a "cheaper" cable, based on a copper-coated aluminum core, we make no compromises on quality to ensure you receive top value and performance for your network cable investment.

This Cat 5e cable is constructed with 24 gauge copper wire, to support a broad range of Ethernet applications such as Power over Ethernet (PoE). Because we use a high quality copper wire, our cables easily sustain the power required for Power over Ethernet applications, whereas the inferior quality offered by copper-coated aluminum cables may be subject to insufficient power delivery, heat buildup, equipment damage and potentially, fire.

This molded patch cable offers high quality connectors comprised of 50-micron gold, to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

Zertifikate Berichte und Kompatibilität



Anwendungen

- Entwickelt für Fast Ethernet-Netzwerke
- Patches von Hub zu Verteiler
- Verbindet Workstation mit Wandsteckdose

Merkmale

- Vergossene RJ45-Stecker
- Sorgfältig entwickelt und getestet für akzeptable Nah-Nebensprechen-Werte (Near End Crosstalk - NEXT)
- Farbige Hauben für Farbcodierung nach Abteilung
- Gefertigt aus hochwertigen Komponenten
- Hochwertiges 24-AWG-Kupferkabel

Hardware

Garantiebestimmungen	Lifetime
Anzahl von Leitern	4 Pair UTP
Typ der Kabelummantelung	PVC - Polyvinyl Chloride
Feuerwiderstandssklasse	Ausgelegt gemäß CMG (Mehrzweck)
Kabeltyp	Vergossen
Verkabelungsstandard	TIA/EIA-568-B.1-2001 T568B

Leistung

Kabelnennwerte	CAT5e - 100 MHz
----------------	-----------------

Steckverbinder

Steckverbinder A	1 - RJ-45
Steckverbinder B	1 - RJ-45

Umgebungsbedingungen

Betriebstemperatur	-20 (-4°F) - 60 (140°F)
Lagertemperatur	0 (32°F) - 30 (86°F)
Feuchtigkeit	60%RH

Physische Eigenschaften

Farbe	Grau
Drahtstärke	24 AWG
Leitungstyp	Feindrähtiges Kupfer
Kabellänge	10.0 ft [3.0 m]
Produktlänge	10.0 ft [3.0 m]
Produktbreite	0.5 in [1.2 cm]
Produkthöhe	0.6 in [1.4 cm]
Produktgewicht	3.6 oz [102.0 g]

Verpackungsinformationen

Paketmenge	1
Paketlänge	6.5 in [16.4 cm]
Paketbreite	7.8 in [19.8 cm]
Pakethöhe	1.0 in [2.5 cm]
Versandgewicht (Verpackung)	3.6 oz [102.0 g]

Verpackungsinhalt

Im Paket enthalten	1 - 10 ft. Cat5e Patch Cable - Gray
--------------------	-------------------------------------

Garantieinformatio
nen

Warranty

Lifetime

* Größe, Aussehen und Spezifikationen sind Änderungen ohne vorherige Ankündigung vorbehalten.