


Cat5e Patch Cable with Molded RJ45 Connectors - 10 ft. - Gray

ID prodotto: M45PATCH10GR

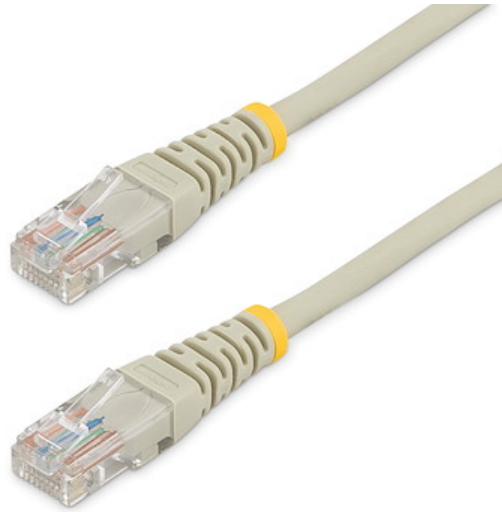

The M45PAT10GR Cat5e Patch Cable (10 ft) meets or exceeds all Cat 5e specifications to ensure reliable Ethernet network connections, and features a durable gray PVC jacket that enables you to color code your network cable runs as needed.

To ensure long-lasting performance, this high quality Cat5e patch cable features molded PVC strain relief that prevents the RJ45 connector termination points from bending at sharp angles - reducing the risk of cable damage, which could decrease network performance.

Constructed of only top quality materials, this Cat5e Patch Cord delivers reliable performance and is backed by our Lifetime Warranty.

StarTech.com Cat5e cables are manufactured using high-quality copper conductors. While many cable manufacturers offer a "cheaper" cable, based on a copper-coated aluminum core, we make no compromises on quality to ensure you receive top value and performance for your network cable investment.

This Cat 5e cable is constructed with 24 gauge copper wire, to support a broad range of Ethernet applications such as Power over Ethernet (PoE). Because we use a high quality copper wire, our cables easily sustain the power required for Power over Ethernet applications, whereas the inferior quality offered by copper-coated aluminum cables may be subject to insufficient power delivery, heat buildup, equipment damage and potentially, fire.

This molded patch cable offers high quality connectors comprised of 50-micron gold, to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

Certificazioni, report e compatibilità



Applicazioni

- Progettato per l'utilizzo con reti Fast Ethernet
- Consente il collegamento dall'hub al pannello di distribuzione
- Consente il collegamento della workstation alla presa a muro

Caratteristiche

- Connettori RJ45 modellati
- Accuratamente realizzato e testato per mantenere le interferenze near-end (NEXT) ampiamente entro i limiti accettabili
- Cappucci colorati per codifica dei colori a sezioni
- Realizzato con componenti di prima qualità
- Filo in rame AWG 24 di alta qualità

Hardware

Norme di garanzia	Lifetime
Numero di conduttori	4 Pair UTP
Tipo guaina cavo	PVC - Polyvinyl Chloride
Classe di resistenza al fuoco	Classe CMG (uso generale)
Tipo cavo	Modellato
Standard cablaggio	TIA/EIA-568-B.1-2001 T568B

Prestazioni

Classe cavo	CAT5e - 100 MHz
-------------	-----------------

Connettore/i

Connettore A	1 - RJ-45
--------------	-----------

	Connettore B	1 - RJ-45
Ambientale		
	Temperatura d'esercizio	-20 (-4°F) - 60 (140°F)
	Temperatura di conservazione	0 (32°F) - 30 (86°F)
	Umidità	60%RH
Caratteristiche fisiche		
	Colore	Grigio
	Diametro filo	24 AWG
	Tipo di conduttore	Rame intrecciato
	Lunghezza del cavo	10.0 ft [3.0 m]
	Lunghezza prodotto	10.0 ft [3.0 m]
	Larghezza prodotto	0.5 in [1.2 cm]
	Altezza prodotto	0.6 in [1.4 cm]
	Peso prodotto	3.6 oz [102.0 g]
Informazioni confezione		
	Quantità confezione	1
	Lunghezza Confezione	6.5 in [16.4 cm]
	Larghezza del Pacco	7.8 in [19.8 cm]
	Altezza del Pacco	1.0 in [2.5 cm]
	Peso spedizione (confezione)	3.6 oz [102.0 g]
Contenuto della confezione		
	Incluso nella confezione	1 - 10 ft. Cat5e Patch Cable - Gray

Informazioni sulla
garanzia

Warranty

A vita

* L'aspetto e le specifiche dell'articolo sono soggetti a modifiche senza preavviso.