


Cat5e Patch Cable with Molded RJ45 Connectors - 10 ft. - Gray

Productcode: M45PATCH10GR

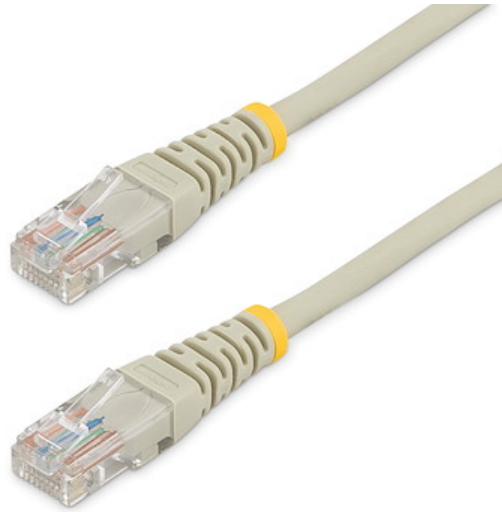

The M45PAT10GR Cat5e Patch Cable (10 ft) meets or exceeds all Cat 5e specifications to ensure reliable Ethernet network connections, and features a durable gray PVC jacket that enables you to color code your network cable runs as needed.

To ensure long-lasting performance, this high quality Cat5e patch cable features molded PVC strain relief that prevents the RJ45 connector termination points from bending at sharp angles - reducing the risk of cable damage, which could decrease network performance.

Constructed of only top quality materials, this Cat5e Patch Cord delivers reliable performance and is backed by our Lifetime Warranty.

StarTech.com Cat5e cables are manufactured using high-quality copper conductors. While many cable manufacturers offer a "cheaper" cable, based on a copper-coated aluminum core, we make no compromises on quality to ensure you receive top value and performance for your network cable investment.

This Cat 5e cable is constructed with 24 gauge copper wire, to support a broad range of Ethernet applications such as Power over Ethernet (PoE). Because we use a high quality copper wire, our cables easily sustain the power required for Power over Ethernet applications, whereas the inferior quality offered by copper-coated aluminum cables may be subject to insufficient power delivery, heat buildup, equipment damage and potentially, fire.

This molded patch cable offers high quality connectors comprised of 50-micron gold, to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

Certificaties, rapporten en compatibiliteit



Toepassingen

- Ontworpen voor gebruik met Fast Ethernet-netwerken
- Voor het verbinden van een hub met een distributiepaneel
- Voor het verbinden van een werkstation met een wandcontactdoos

Eigenschappen

- Gegoten RJ45-connectoren
- Zorgvuldig ontworpen en gefabriceerd om Near End Crosstalk (NEXT) binnen aanvaardbare grenzen te houden
- Gekleurde afscherming voor eventuele kleurcodering
- Vervaardigd uit hoogwaardige onderdelen
- Hoogwaardig koperdraad met 0,5 mm dikte

Hardware

Garantiebeleid	Lifetime
Aantal geleiders	4 Pair UTP
Type kabelmantel	PVC - Polyvinyl Chloride
Brandbestendigheid	CMG goedgekeurd (algemeen doel)
Type kabel	Gegoten
Kabelstandaard	TIA/EIA-568-B.1-2001 T568B

Prestaties

Kabelspecificatie	CAT5e - 100 MHz
-------------------	-----------------

Connector(en)

Connector A	1 - RJ-45
-------------	-----------

Connector B 1 - RJ-45

Gebruiksomgeving

Bedrijfstemperatuur	-20 (-4°F) - 60 (140°F)
Opslagtemperatuur	0 (32°F) - 30 (86°F)
Vochtigheid	60%RH

Fysieke eigenschappen

Kleur	Grijs
Draaddikte	24 AWG
Type geleider	Gevlochten koper
Kabellengte	10.0 ft [3.0 m]
Lengte product	10.0 ft [3.0 m]
Breedte product	0.5 in [1.2 cm]
Hoogte product	0.6 in [1.4 cm]
Gewicht product	3.6 oz [102.0 g]

Verpakkingsinformatie

Verpakkingsaantal	1
Lengte Verpakking	6.5 in [16.4 cm]
Breedte Verpakking	7.8 in [19.8 cm]
Hoogte Verpakking	1.0 in [2.5 cm]
Verzendgewicht (verpakt)	3.6 oz [102.0 g]

Wat wordt er meegeleverd

Meegeleverd	1 - 10 ft. Cat5e Patch Cable - Gray
-------------	-------------------------------------

Garantiebepalingen

Warranty

Levenslang

* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.