

3 ft Mini DisplayPort to DVI Active Adapter Converter Cable - mDP to DVI 1920x1200 - White

**Product ID:** MDP2DVIMM3WS



The MDP2DVIMM3WS 3ft active Mini DisplayPort to DVI adapter cable lets you directly connect your Mini DP video source (such as any of your MacBook or Microsoft Surface Pro devices with mDP) directly to a nearby DVI monitor or projector, saving the expense of additional adapters while eliminating the clutter of excess cable. The converter features a stylish white design, that is well-suited for connecting Mac computers.

For guaranteed compatibility with virtually any Mini DisplayPort output the active Mini DP to DVI adapter supports multimode (DP++) as well as single-mode DisplayPort signals. Unlike passive adapters, this ensures the MDP2DVIMM3WS can be used with graphics cards that are not capable of outputting multimode DP++ signals, such as ATI Eyefinity cards.

Compatible with Intel Thunderbolt, when connected directly to a supporting DisplayPort over Thunderbolt I/O port, the adapter supports resolutions up to 1920 x 1200.

The MDP2DVIMM3WS is backed by a 3-year StarTech.com warranty and free lifetime technical support.

Note:

This adapter is not compatible for use with the Apple Cinema Display.

## Certifications, Reports and Compatibility

### Applications

- Use with single-mode Mini DisplayPort video outputs that are not capable of outputting multimode DP++ signals, such as ATI Eyefinity video cards
- Connect your DVI display device (monitor, projector) directly to a Mini DisplayPort output device

- Ideal for using your DVI monitor as a secondary display

## Features

- Active Mini DisplayPort to DVI conversion
- 1x Male DisplayPort connector, 1x Male DVI connector
- Compatible with Intel Thunderbolt devices that are capable of outputting a DisplayPort signal
- Supports resolutions up to 1920 x 1200
- Plug-and-play Installation

---

### Prominence

Warranty	3 Years
Description CDW 75 - 1st Line	StarTech.com 3ft Mini DisplayPort to DVI Adapter Cable, Active mDP to DVI-D

---

### Hardware

Active or Passive Adapter	Active
AV Input	Mini DisplayPort - 1.2
AV Output	DVI-D - Single-Link
Audio	No
Chipset ID	Parade - PS171

---

### Performance

Maximum Cable Length	36.0 in [91.5 cm]
Maximum Digital Resolutions	1920 x 1200
Supported Resolutions	1024 x 768
	1280 x 720
	1920 x 1080
	1920 x 1200
Wide Screen Supported	Yes
Audio Specifications	DVI - No Audio Support



MTBF 1,291,679 hours

---

**Connector(s)**

Connector A Mini-DisplayPort (20 pin)

Connector B DVI-D (25 pin)

---

**Special Notes / Requirements**

System and Cable Requirements Some dual-link DVI monitors manufactured prior to 2014 may have limited resolutions support when used with this adapter.

This adapter is not compatible for use with the Apple Cinema Display.

---

**Environmental**

Operating Temperature 0C to 60C (32F to 140F)

Storage Temperature -10C to 70C (14F to 158F)

Humidity 40%-85%RH

---

**Physical Characteristics**

Color White

Cable Length 36.3 in [92.2 cm]

Product Length 36.3 in [92.2 cm]

Product Width 1.6 in [40 mm]

Product Height 0.6 in [16 mm]

Weight of Product 2.5 oz [71.6 g]

---

**Packaging Information**

Package Length 8.7 in [22 cm]


Package Width 7.9 in [20 cm]

Package Height 0.6 in [15 mm]

Shipping (Package) Weight 3.0 oz [84 g]

---

**What's in the Box**

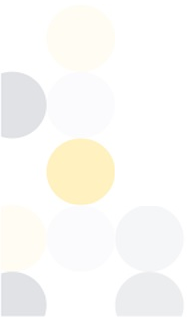

Included in Package

Active DisplayPort to DVI Adapter

---

***\*Product appearance and specifications are subject to change without notice.***

