


MPO/MTP to LC Breakout Cable - Plenum-Rated - OM3, 40Gb - Push/Pull-Tab - 3 m (10 ft.)

Productcode: MPO8LCPL3M

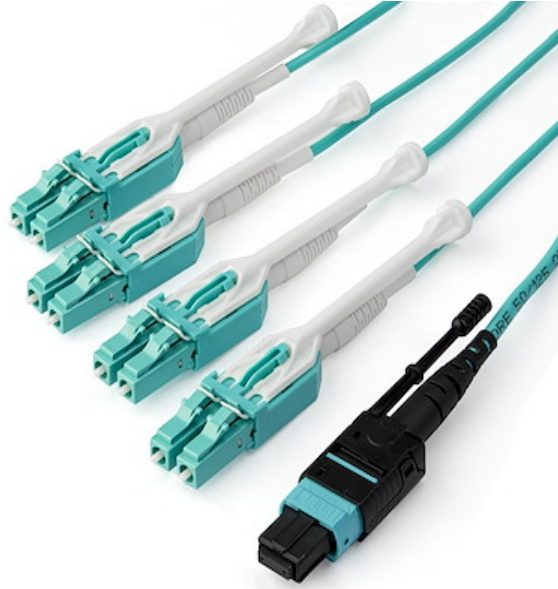

This MPO/MTP to 8x LC breakout cable lets you fan out a single 40Gbps connection from a 40GBase-SR4 QSFP+ transceiver to four 10Gbps LC SFP+ transceivers.

The push-and-pull tabs optimize accessibility and let you install or remove the connectors with one hand, without having to use additional tools. Plus, the slim uniboot design of the LC connectors saves space and improves cable management.

The MPO cable is housed in a plenum-rated jacket and is ideal for installations where CMP fire rating is required.

Each OM3 fiber cable has been individually tested for insertion loss and return loss. The full test report is included in each cable bag.

The MPO8LCPL3M from StarTech.com is backed by a lifetime warranty.

## Certificaties, rapporten en compatibiliteit

### Toepassingen

- Use in 10/40 Gigabit Ethernet and fiber channel applications
- Fan out a single 40Gbps MPO/MTP connection to four 10Gbps LC connections on devices such as fiber patch panels, hubs, switches, media converters, and routers
- Used with 40GBase-SR4 networking hardware

## Eigenschappen

- Obtain higher port density with eight LC network connections combined into a single MPO/MTP connector
- Optimize accessibility and install or remove connectors with one hand using the push-and-pull tabs
- Save space and improve cable management with slim uniboot connectors
- Get test data for your fiber cable - an insertion loss and return loss test report is included in each cable bag

---

### Hardware

Garantiebeleid	Lifetime
Brandbestendigheid	CMP goedgekeurd (luchtruimtes)
Glasvezelformaat	50/125

---

### Prestaties

Glasvezelclassificatie	OM3
Glasvezeltype	Multi-Mode

---

### Connector(en)

Connector A	MPO/MTP
Connector B	Glasvezel LC duplex

---

### Gebruiksomgeving

Bedrijfstemperatuur	-10°C to 70°C (14°F to 158°F)
Opslagtemperatuur	-10°C to 70°C (14°F to 158°F)
Vochtigheid	55 65%RH

---

### Fysieke eigenschappen

Kleur	Aqua
Kabellengte	9.8 ft [3 m]
Lengte product	9.8 ft [3 m]



Breedte product	0.5 in [13.8 mm]
Hoogte product	0.3 in [8 mm]
Gewicht product	1.8 oz [52 g]

---

Verpakkingsinformatie

Package Length	7.9 in [20 cm]
Package Width	8.7 in [22 cm]
Package Height	0.4 in [10 mm]
Verzendgewicht (verpakt)	2.2 oz [62 g]

---

Wat wordt er meegeleverd

Meegeleverd	fiber optic cable
-------------	-------------------

---

\* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.

