


3 Port PCI Low Profile 1394a FireWire Adapter Card

Product ID: PCI1394_2LP

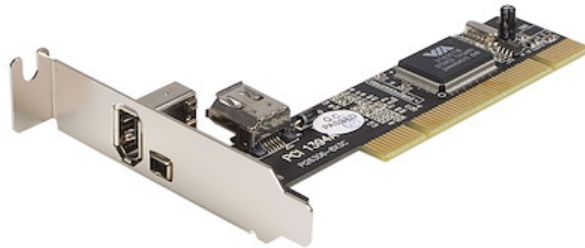

This 3 Port PCI Low-Profile/Half-Height 1394a FireWire Adapter Card turns a motherboard PCI slot into two external IEEE 1394a FireWire slots (1x6-pin, 1x4-pin), and provides an internal (6-pin) FireWire port that can be used in place of the external 6-pin connector - a cost-effective solution that lets you connect any FireWire 400 device to your desktop computer.

Compatible with either Mac or PC computers, the 1394a FireWire card can be installed in small/micro form factor computer cases, and includes both standard and low profile/half-height brackets for easy installation.

A practical solution for connecting iPods, MP3 players, portable drives, digital camcorders and more to your desktop computer, the FireWire 400 adapter card supports hot-swappable connectivity, allowing you to plug, unplug, and swap your FireWire peripherals with ease.

A versatile FireWire video editing solution, the adapter card can be installed in a PCI 5V or PCI-x 3.3V slot.

Certifications, Reports and Compatibility

Applications

- Add a high-speed FireWire port to a desktop or small form factor system without any FireWire ports
- Connect a digital camera to a PCI enabled desktop to download photos and video
- Connect a high-speed external hard drive to an PCI enabled system

Features

- Two external FireWire400 ports and one shared internal port with support for transfer rates up to 400 Mbps

- Complaint with IEEE 1394-1995, 2000 and OHCI 1.1 standards
- Compliant with PCI revision 2.2 specifications
- Plug-and-Play and Hot-Swap compatible
- Full/Low Profile installation brackets included

Hardware

Warranty	Lifetime
Ports	2
Interface	FireWire 400 (1394a)
Bus Type	PCI / PCI-X (5 / 3.3V)
Card Type	Low Profile (SP bracket incl.)
Industry Standards	PCI 2.1
	IEEE 1394
	IEEE 1394a
	OHCI
Chipset ID	VIA/VLI - VT6307

Performance

Maximum Data Transfer Rate	400 Mbps
----------------------------	----------

Connector(s)

Connector Type(s)	PCI / PCI-X (Universal 3.3 & 5V, 32-bit)
Internal Ports	FireWire 400 (6 pin, IEEE 1394a)
External Ports	FireWire 400 (6 pin, IEEE 1394a)
	FireWire 400 (4 pin, IEEE 1394a)

Software

OS Compatibility	Windows 8 / 8.1 (32/64bit), 7 (32/64), Vista (32/64), XP (32/64), 98SE, 2000
	Windows Server 2012, 2003



Mac OS 10.x (Tested up to 10.4)

Linux

Special Notes / Requirements

System and Cable Requirements 1 x Free PCI slot

Note The internal port and the top external port share the same connection, meaning that only one of these two ports can be used at a time. Configured with low bracket and standard bracket included

Physical Characteristics

Weight of Product 4.9 oz [140 g]

Packaging Information

Package Length 7.1 in [18 cm]

Package Width 1.4 in [36 mm]

Package Height 5.1 in [13 cm]

Shipping (Package) Weight 7.8 oz [220 g]

What's in the Box

Included in Package 2 Port Low Profile Firewire Card

4-pin to 6-pin Firewire Cable

Full Profile Bracket

Instruction Manual

****Product appearance and specifications are subject to change without notice.***

