

4 Port PCI 1394a FireWire Adapter Card with Digital Video Editing Kit

Product ID: PCI1394_4



This 4 Port PCI IEEE 1394 FireWire 400 Adapter Card turns a motherboard PCI slot into four IEEE 1394a FireWire 6-pin female ports (1 internal, 3 external) - a cost-effective solution that lets you connect any FireWire 400 device that uses a 6-pin connector to your desktop computer.

The card can be installed in either Mac or PC computers, providing a practical solution for connecting iPods, MP3 players, portable drives, digital camcorders and more. The adapter card supports hot-swappable connectivity, allowing you to plug, unplug, and swap your FireWire peripherals with ease, saving time and hassle.

The 4 port FireWire PCI adapter card includes a copy of ULEAD's VideoStudio SE Basic video editing software, making it easy to capture and edit video from your digital video camcorder.

Certifications, Reports and Compatibility

Applications

- Add a high-speed FireWire port to a desktop without any FireWire ports
- Connect a digital camera to a desktop with a PCI slot to download photos and video
- Connect a external FireWire hard drive or optical drive to a PCI-enabled system

Features

- 3 external, 1 shared internal FireWire400 port, with supported data transfer rates up to 400 Mbps
- Compliant with IEEE 1394a - 2000 as well as 1394-1995 standards

- Includes Video Editing kit: Ulead Video Studio SE and FireWire cable
- Plug-and-Play and hot-swap compatible

Hardware

Warranty	Lifetime
Ports	4
Interface	FireWire 400 (1394a)
Bus Type	PCI (5 Volt)
Card Type	Standard Profile
Industry Standards	IEEE 1394-1995 IEEE 1394a OHCI PCI 2.1
Chipset ID	VIA/VLI - VT6306

Performance

Maximum Data Transfer Rate	400 Mbps
----------------------------	----------


Connector(s)

Connector Type(s)	PCI (5V, 32-bit)
Internal Ports	FireWire 400 (6 pin, IEEE 1394a)
External Ports	FireWire 400 (6 pin, IEEE 1394a)

Software

OS Compatibility	Windows 2000, XP, Vista, 7, 8, 8.1, 10 Windows Server 2003, 2008 R2, 2012, 2012 R2, 2016 Mac OS 8.6 to 10.4 Linux 2.6 to 4.4.x (LTS Versions Only)
Microsoft WHQL Certified	Yes

Special Notes / Requirements

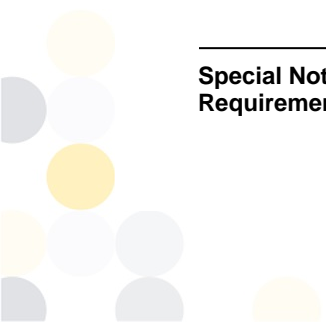

System and Cable Requirements	Unused PCI slot
-------------------------------	-----------------

Note	The internal port and the top external port cannot be used at the same time. Only one or the other is active at a time.
------	---

Physical Characteristics

Product Length	4.7 in [12 cm]
Product Width	0.7 in [18 mm]
Product Height	3.1 in [80 mm]
Weight of Product	2.5 oz [70 g]

Packaging Information

Package Length	6.5 in [16.6 cm]
Package Width	5.6 in [14.1 cm]
Package Height	1.2 in [30 mm]
Shipping (Package) Weight	6.7 oz [189 g]

What's in the Box

Included in Package	PCI Firewire Card
	Firewire cable 4pin-6pin
	Driver and Software CD
	Instruction Manual

****Product appearance and specifications are subject to change without notice.***

