


4 port PCI 1394a FireWire Adapter Card - 3 External 1 Internal

Product ID: PCI1394MP

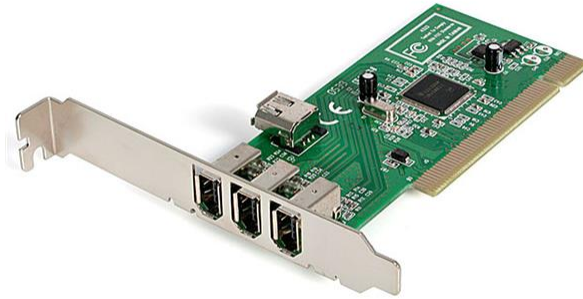

This 4 Port (3 External/1 Internal) PCI 1394 FireWire Adapter Card lets you connect iPods, MP3 players, portable drives, digital camcorders and more to your desktop computer.

The FireWire adapter card supports hot-swapping, so you'll be able to plug, unplug, and swap your FireWire peripherals with ease.

Guaranteed to work with both PCs and Macs, the 4 port PCI FireWire Adapter Card is backed by StarTech.com's Lifetime Warranty and FREE LIFETIME tech support. Plus, the adapter provides both standard profile and low profile/half-height brackets for adapting to slimline or small form factor system applications.

Please Note: If you require digital video editing software, StarTech.com offers a complete FireWire kit with our PCI1394_4 card. This software is compatible with Windows operating systems only. WHQL Certified - Designed to work with Microsoft Windows XP

Certifications, Reports and Compatibility

Applications

- Add a high-speed FireWire port to a full or small form factor desktop without any FireWire ports
- Connect a digital camera to a desktop with a PCI slot to download photos and video
- Connect a external FireWire hard drive or optical drive to a PCI-enabled system

Features

- 3 external, 1 shared internal FireWire400 port, with supported data transfer rates up to 400 Mbps

- Compliant with IEEE 1394a - 2000 as well as 1394-1995 standards
- Includes Low Profile installation bracket
- Plug-and-Play and hot-swap compatible

Hardware

Warranty	Lifetime
Ports	3
Interface	FireWire 400 (1394a)
Bus Type	PCI (5 Volt)
Card Type	Standard Profile (LP bracket incl.)
Industry Standards	PCI 2.1 IEEE 1394a OHCI
Chipset ID	Texas Instruments - TSB12LV26

Performance

Maximum Data Transfer Rate	400 Mbps
----------------------------	----------

Connector(s)

Connector Type(s)	PCI (5V, 32-bit)
Internal Ports	FireWire 400 (6 pin, IEEE 1394a)
External Ports	FireWire 400 (6 pin, IEEE 1394a)

Software

OS Compatibility	Windows 2000, XP, Vista, 7, 8, 8.1, 10 Windows Server 2003, 2008 R2, 2012, 2016, 2019 Mac OS X 10.x (tested up to 10.4) Linux 3.5.x to 4.11.x <i>LTS Versions only</i>
Microsoft WHQL Certified	Yes

Physical



Characteristics

Material	Steel
Product Length	4.8 in [12.3 cm]
Product Width	0.7 in [18 mm]
Product Height	3.1 in [80 mm]
Weight of Product	1.9 oz [53 g]

Packaging Information

Package Length	5.7 in [14.5 cm]
Package Width	6.9 in [17.5 cm]
Package Height	1.2 in [31 mm]
Shipping (Package) Weight	4.3 oz [122 g]

What's in the Box

Included in Package	PCI FireWire Card
	Instruction Manual
	Low Profile Bracket

****Product appearance and specifications are subject to change without notice.***

