


Value 1 Port PCI Parallel Adapter Card

Produkt ID: PCI1P

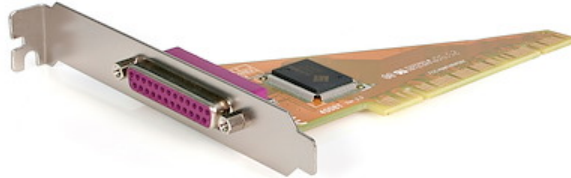

The PCI1P value priced EPP/ECP parallel card adds one IEEE 1284 port to your PC, with data transfer speeds of up to 2.7 Mbps – up to 3 times faster than on-board parallel ports.

Installation is a breeze with plug and play support and drivers for Windows® 7, Vista, XP, ME, 2000, 98, 95, NT4, DOS® and Linux®. IRQ sharing and hot swapping capabilities guarantee convenient, hassle-free connections to any parallel peripheral.

Backed by a StarTech.com lifetime warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet



Användning

- Connects any parallel peripheral including printers, scanners, CD-R/RWs, Zip® drives, and memory card readers

Funktioner

- Supports EPP, ECP, SPP and BPP
- Data transfer rates of up to 2.7 Mbits/sec maximizes the performance of your peripherals
- IRQ sharing eliminates conflicts between multiple cards
- Easy plug and play installation

Hårdvara

Garantipolicy	Lifetime
Portar	1
Gränssnitt	Parallell
Busstyp	PCI / PCI-X (5 / 3.3V)
Korttyp	Standardprofil
Porttyp	Inbyggd på kort
Industristandarder	IEEE-1284
Chipset-ID	Sunix - SUN1888

Prestanda

Maximal dataöverföringshastighet	2.7Mbps
Stödda protokoll	EPP, ECP, SPP, BPP

Kontakt(er)

Kontakttyp(er)	1 - PCI/PCI-X (universell 3,3 & 5 V, 32-bitars)
Externa portar	1 - DB-25 (25-stifts, D-Sub)

Mjukvara

OS-kompatibilitet	Windows® DOS, 95, 98SE, ME, XP, Vista, 7, 8, 8.1, 10 Linux 3.5.x to 4.4.x LTS Versions only
Microsoft WHQL-certifierad	Ja

Särskilda
anmärkningar/krav

System- och kabelkrav Unused PCI slot

Utseende

Produktlängd	4.7 in [12 cm]
Produkthöjd	2.2 in [5.5 cm]

Förpackning

Paketets längd	8.3 in [21 cm]
Package Width	1.5 in [38 mm]
Paketets höjd	5.6 in [14.3 cm]
Fraktvikt (förpackning)	5.6 oz [160 g]

Vad det är i lådan

Ingår i paketet	1 - 1 Port PCI Parallel Card
	1 - Driver CD
	1 - User Manual

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.