


2 Port PCI Parallel Adapter Card - EPP/ECP

Produkt ID: PCI2PECP

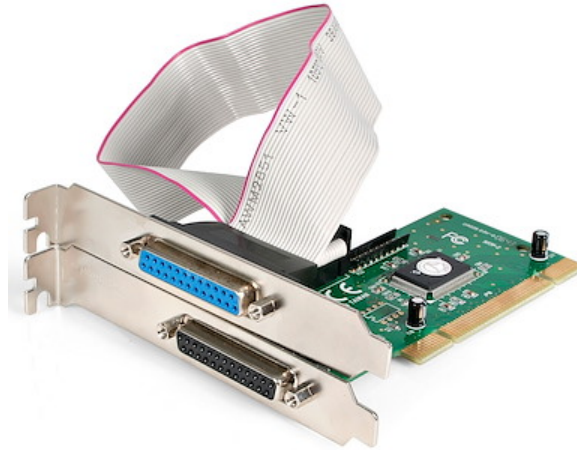

The PCI2PECP 2 Port EPP/ECP PCI Parallel Adapter Card can be installed in an available PCI slot, adding two IEEE 1284 ports to your PC and supporting data transfer speeds of up to 1.5 Mbps (up to 3 times faster than built-in parallel ports).

Installing the EPP/ECP parallel adapter card is easy, with support for Windows® 8, 7, Vista, XP, ME, 98SE, 95, DOS, Windows Server® 2012, and Linux. Plus, IRQ sharing and plug and play capabilities guarantee convenient, hassle-free connections to any parallel peripheral.

A complete dual profile solution, this parallel adapter card provides both a standard bracket and a low-profile/half-height bracket for adapting to slimline or small form factor system applications.

Backed by a StarTech.com lifetime warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet



Användning

- Connects any parallel peripheral including printers, scanners, CD-R/RWs, Zip® drives, and memory

card readers

Funktioner

- Includes half-height/low profile mounting bracket
- Easy plug and play installation
- Data transfer rates of up to 1.5 Mbps
- Compatible with Linux and all versions of Windows® including Windows® XP
- IRQ sharing eliminates conflicts between multiple cards
- Supports EPP, ECP, SPP and BPP
- Installation scripts available for Linux RedHat 7.2, SuSE 7.3 and Mandrake 8.2

Hårdvara

Garantipolicy	Lifetime
Portar	2
Gränssnitt	Parallell
Busstyp	PCI / PCI-X (5 / 3.3V)
Korttyp	Standardprofil (inkl. LP-fäste)
Porttyp	Inbyggd på kort
Industristandarder	IEEE-1284
Chipset-ID	ASIX - MCS9815CV

Prestanda

Maximal dataöverföringshastighet	1.5 Mbps
Stödda protokoll	EPP, ECP, SPP, BPP, PS2

Kontakt(er)

Kontakttyp(er)	1 - PCI/PCI-X (universell 3,3 & 5 V, 32-bitars)
Externa portar	2 - DB-25 (25-stifts, D-Sub)

Mjukvara

OS-kompatibilitet	Windows® DOS, 95, 98SE, ME, XP, Vista, 7, 8, 8.1, 10, 11
	Windows Server® 2003, 2008 R2, 2012
	Linux 3.5.x to 4.11.x LTS Versions only

Särskilda
anmärkningar/krav

System- och kabelkrav	Unused PCI slot
-----------------------	-----------------

Utseende

Färg	Grön
Kabinetttyp	Stål
Produktlängd	4.7 in [12.0 cm]
Produktbredd	0.8 in [2.0 cm]
Produkthöjd	4.7 in [12.0 cm]
Produktvikt	2.5 oz [70.0 g]

Förpackning

Förpackningsantal	1
Paketets längd	6.7 in [17.0 cm]
Paketets bredd	5.7 in [14.4 cm]
Paketets höjd	1.2 in [3.0 cm]
Fraktvikt (förpackning)	6.8 oz [192.0 g]

Vad det är i lådan

Ingår i paketet	1 - 2 Port PCI Parallel Card
	2 - Low Profile Brackets
	1 - Ribbon Cable w/DB25F Plate
	1 - Driver CD

1 - Instruction Manual

Warranty
Information

Warranty

Livslängd

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.