


## 2 Port PCI RS232 Serial Adapter Card w/ 16950 UART - Dual Voltage

Produkt ID: PCI2S950DV

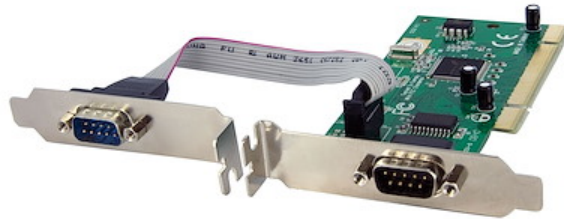

The PCI2S950DV 2 Port Dual Voltage PCI RS232 Serial Adapter Card w/ 16950 UART - lets you add 2 RS-232 serial ports using a PCI expansion slot offering high performance 16950 UART channels/ports for connecting any new or legacy serial peripherals, with data transfer rates of up to 460kbps.

A cost-effective solution for connecting serial modems, POS devices, printers, ISDN terminal adapters and more, the PCI serial card offers dual voltage support, allowing you to use a PCI (5V) or PCI-X (3.3V) slot for installation. The RS232 card also provides broad operating system support, IRQ sharing and a plug and play PCI interface with included standard and low profile slot brackets to guarantee convenient, hassle-free serial device connections on almost any system.

Backed by a StarTech.com lifetime warranty and free lifetime technical support.

### Certifikat, rapporter och kompatibilitet



### Användning

- Manufacturing (CNC machinery, process control equipment, bar code scanners, serial printers)

- POS (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)
- Consumer (modems, PDAs, digital cameras, printers)
- Security (UPS control, access key panels, video cameras, card readers, modems)
- Casino (video lottery terminals, slot machines)
- Environmental Control (lighting, temperature, clocks)
- Healthcare (patient monitoring equipment, nurses' stations, modems)
- Hotel Front Desk (serial printers, bar code scanners, keyboard, mouse, receipt printer, credit/debit card reader)
- Hospitality/Restaurant (credit card/debit card reader, serial printers)
- ISDN Networking

## Funktioner

- Two high performance 16C950 UART channels
- Maximum data transfer rate of 460 Kbps
- 128-byte deep FIFO per transmitter and receiver
- PCI 3.0 and Power Management 1.1 compliant
- Automated in-band software flow control using programmable Xon/Xoff in both directions
- Automated out-of-band hardware flow control using RTS / CTS and/or DSR / DTR
- UART's fully compatible with 16C550 type devices

---

## Hårdvara

| Garantipolicy | Lifetime                        |
|---------------|---------------------------------|
| Portar        | 2                               |
| Gränssnitt    | Seriell                         |
| Busstyp       | PCI / PCI-X (5 / 3.3V)          |
| Korttyp       | Standardprofil (inkl. LP-fäste) |
| Porttyp       | Inbyggd på kort                 |

|                              |                                                                                                                                          |                        |
|------------------------------|------------------------------------------------------------------------------------------------------------------------------------------|------------------------|
| Chipset-ID                   |                                                                                                                                          | PLX/Oxford - OXuPCI952 |
| Prestanda                    |                                                                                                                                          |                        |
| Seriellt protokoll           | RS-232                                                                                                                                   |                        |
| Maximal överföringshastighet | 460.8 kbps                                                                                                                               |                        |
| Databitar                    | 5, 6, 7, 8, 9                                                                                                                            |                        |
| FIFO                         | 128 Bytes                                                                                                                                |                        |
| Flödeskontroll               | Hardware, Auto Xon/Xoff, None                                                                                                            |                        |
| Paritet                      | None, Even, Odd                                                                                                                          |                        |
| Kontakt(er)                  |                                                                                                                                          |                        |
| Kontakttyp(er)               | 1 - PCI/PCI-X (universell 3,3 & 5 V, 32-bitars)                                                                                          |                        |
| Externa portar               | 2 - DB-9 (9-stifts, D-Sub)                                                                                                               |                        |
| Mjukvara                     |                                                                                                                                          |                        |
| OS-kompatibilitet            | Windows® 95, 98SE, ME, XP, Vista, 7, 8, 8.1, 10, 11<br>Windows Server® 2003, 2008 R2, 2012, 2016<br>Linux 3.5 to 4.4.x LTS Versions only |                        |
| Särskilda anmärkningar/krav  |                                                                                                                                          |                        |
| Obs.                         | Crystal will need to be adjusted to achieve 460 Kbps                                                                                     |                        |
| Miljö                        |                                                                                                                                          |                        |
| Drifttemperatur              | -10°C to 80°C (14°F to 176°F)                                                                                                            |                        |
| Förvaringstemperatur         | -20°C to 100°C (-4°F to 212°F)                                                                                                           |                        |
| Luftfuktighet                | 5~85% RH                                                                                                                                 |                        |
| Utseende                     |                                                                                                                                          |                        |
| Färg                         | Grön                                                                                                                                     |                        |
| Produktlängd                 | 4.1 in [10.5 cm]                                                                                                                         |                        |
| Produktbredd                 | 0.8 in [2 cm]                                                                                                                            |                        |

Produkthöjd 4.7 in [12 cm]

Produktvikt 1.9 oz [55 g]

#### Förpackning

Förpackningsantal 1

Paketets längd 5.8 in [14.8 cm]

Paketets bredd 2.3 in [58 mm]

Paketets höjd 7.7 in [19.5 cm]

Fraktvikt (förpackning) 0.4 lb [0.2 kg]

#### Vad det är i lådan

Ingår i paketet 1 - 2 Port PCI / PCI-X Serial Card

2 - Low Profile Bracket

1 - Driver CD

1 - Instruction Manual

#### Warranty Information

Warranty Livslängd

\* Produkters utseende och specifikationer kan komma att ändras utan förvarning.