


5 Port PCI High Speed USB 2.0 Adapter Card

Produkt ID: PCI420USB

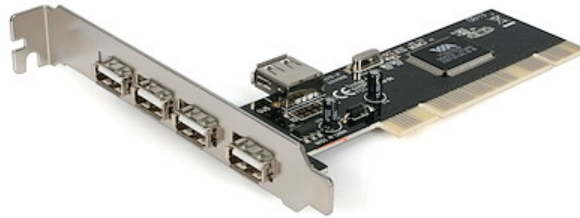


This PCI-based High Speed USB 2.0 Adapter Card adds five USB 2.0 'A' Female ports (1 internal, 4 external) to your PCI-capable PC.

Supported by popular operating systems including Windows 98SE/ME/2000/XP/Vista, the PCI USB 2.0 card is a versatile solution that lets you add USB 2.0 connections without having to upgrade the system motherboard.

A convenient and time-saving solution, the PCI USB card is WHQL certified to simplify driver installation in Windows XP operating environments, and supports USB device hot-swapping - allowing you to connect/disconnect USB peripherals without having to power down the computer.

Designed and constructed to provide long-lasting USB capability, the adapter card is backed by StarTech.com's Lifetime Warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

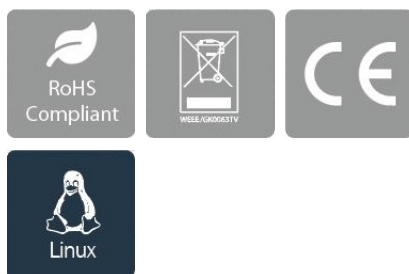

Användning

- Expand a PCI-based system's USB capabilities with four additional external USB ports
- Add additional USB bandwidth to a system that already uses many USB devices/hubs
- Connect additional external hard drives, CD/DVD drives, MP3 players, printers, scanners, webcams, game controllers, digital cameras, etc. to a computer system

Funktioner

- Provides four external USB 2.0 ports and one shared internal port
- Fully compliant with USB 2.0 specifications, with support for transfer rates up to 480 Mbps
- Backwards compatible with USB 1.0/1.1 devices
- Compliant with PCI revision 2.2 specification
- Supports up to 127 USB devices per port (requires additional USB hubs)
- Plug-and-Play and Hot-Swap compatible

Hårdvara

Garantipolicy	Lifetime
Portar	5
Gränssnitt	USB 2.0
Busstyp	PCI / PCI-X (5 / 3.3V)
Korttyp	Standardprofil
Industristandarder	OHCI
	EHCI
	PCI 2.2
Chipset-ID	VIA/VLI - VT6212

Prestanda

Maximal dataöverföringshastighet	480 Mbps
----------------------------------	----------

Kontakt(er)

Kontakttyp(er)	1 - PCI/PCI-X (universell 3,3 & 5 V, 32-bitars)
Interna portar	1 - USB 2.0 Type-A (4 stift, 480 Mbps)
Externa portar	4 - USB 2.0 Type-A (4 stift, 480 Mbps)

Mjukvara

OS-kompatibilitet	Windows® 2000, XP Linux 3.5.x till 4.11.x Endast LTS-versioner
Microsoft WHQL-certifierad	Ja

Särskilda anmärkningar/krav

System- och kabelkrav	Unused PCI slot
Obs.	The internal USB 2.0 is shared with the top-most external USB 2.0 port, therefore only one of those ports may be used at a time.

Miljö

Drifttemperatur	0°C to 70°C (32°F to 158°F)
Förvaringstemperatur	-40°C to 85°C (-40°F to 185°F)
Luftfuktighet	10~90% RH

Utseende

Produktlängd	4.7 in [12 cm]
Produkthöjd	3.7 in [9.5 cm]
Produktvikt	1.1 oz [30 g]

Förpackning

Förpackningsantal	1
Paketets längd	8.3 in [21.2 cm]
Paketets bredd	1.7 in [42 mm]
Paketets höjd	5.7 in [14.5 cm]
Fraktvikt (förpackning)	0.2 lb [0.1 kg]

Vad det är i lådan

Ingår i paketet

1 - PCI USB card

1 - Instruction Manual

Warranty
Information

Warranty

Livslängd

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.