


## 5 Channel Low Profile PCI Sound Adapter Card – 24 Bits

**Product ID:** PCISOUND5LP

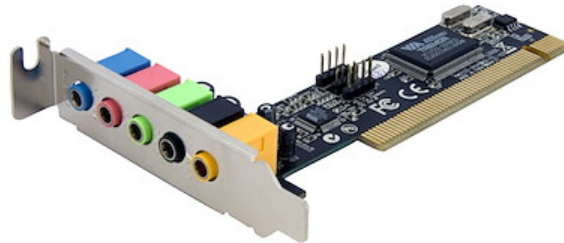

This 5 Channel PCI Sound Adapter Card is the ideal sound solution for low profile/small form factor PC computers, supporting full-duplex operation with 6 outbound streams and 2 simultaneous input streams. Offering everything you need to take your multimedia experience to the next level, the 5-channel sound card supports the latest Dolby Digital EX and DTS 5.1 Channel DVD soundtracks, and 96Khz/24bit audio playback. The sound card includes Windows WDM supported drivers, which save both time and hassle, allowing you to add high quality audio in minutes. Equipped with a low profile bracket, the 5-channel Sound Card also includes a standard profile (full-height) mounting bracket and is PCI v2.2 compliant, so it can be installed in virtually any PCI-capable PC regardless of the size of the computer case - a cost-effective HTPC (Home Theater PC) solution! This high quality 5.1 Surround Sound card is backed by StarTech.com's 2-year warranty and free lifetime technical support.

### **Certifications, Reports and Compatibility**

#### **Applications**

- Replace failed or stereo-only onboard audio for a small form factor or full desktop system
- Upgrade to 5.1 audio for a desktop without onboard audio or less than 5.1 surround
- Build a inexpensive home theater PC or multimedia PC with surround sound capabilities

#### **Features**

- 5.1 channel surround sound output via 3.5mm mini-jacks
- DirectSound 3 hardware acceleration
- Support for Dolby Digital EX and DTS ES 5.1 channel playback

- Full-Duplex operation for recording and playback
- Supports up to 96KHz/24-bit playback and 48KHz/16-bit recording sampling rates
- Compliant with PCI revision 2.2 specification
- Low/Full Profile installation brackets included

---

#### Hardware

Warranty	2 Years
Bus Type	PCI (5 Volt)
Card Type	Low Profile (SP bracket incl.)
Chipset ID	VIA/VLI - Tremor VT1723

---

#### Performance

Audio Specifications	Input and Output Connections Line In, Microphone, Front Out, Rear Out, Sub/Center Out
----------------------	--

---

#### Connector(s)

Connector Type(s)	PCI (5V, 32-bit)
Internal Ports	MPC2 (4 pin, Audio)
External Ports	3.5 mm Mini-Jack (3 Position)

---

#### Software

OS Compatibility	Windows 2000/ XP(32/64-bit)/ Server 2003(32/64-bit)/ Server 2008 R2/ Vista(32/64-bit)/ 7(32/64-bit)/ 8(32/64-bit)
------------------	---

---

#### Environmental

Operating Temperature	20C to 50C (68F to 122F)
Storage Temperature	0C to 70C (32F to 158F)
Humidity	20-80% RH

---

#### Physical Characteristics

Product Length	4.8 in [12.1 cm]
Product Width	0.7 in [18 mm]
Product Height	3.1 in [80 mm]



Weight of Product	1.9 oz [55 g]
-------------------	---------------

---

**Packaging Information**

Package Length	6.8 in [17.3 cm]
----------------	------------------

Package Width	1.2 in [31 mm]
---------------	----------------

Package Height	5.6 in [14.2 cm]
----------------	------------------

Shipping (Package) Weight	12.0 oz [340 g]
---------------------------	-----------------

---

**What's in the Box**

Included in Package	5.1 Sound Card with Low Profile Bracket
---------------------	---

Full Profile Bracket
----------------------

Driver CD
-----------

Instruction Manual
--------------------

---

***\*Product appearance and specifications are subject to change without notice.***

