


7 Port PCI USB Card Adapter - TAA

Produkt ID: PCIUSB7

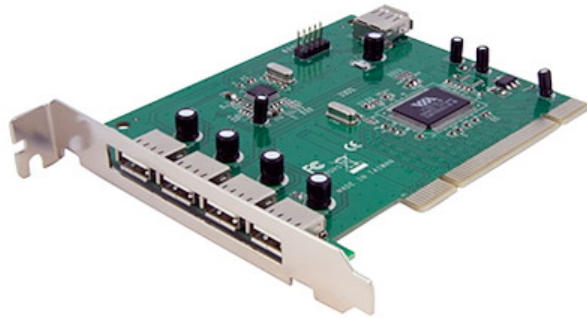

This PCI USB card adds seven USB 2.0 ports (1 internal USB A Female, 2 internal USB motherboard header, and 4 external USB A Female) to your PCI-capable PC.

The PCI USB 2.0 card is a versatile solution that lets you add USB 2.0 connections without having to upgrade the system motherboard.

An all-in-one solution, the PCI USB card supports USB 2.0 device connections for full data transfer speeds of up to 480Mbps, and is backward compatible with USB 1.1 devices (max. transfer rate 12Mbps), allowing you to connect any USB device to the computer without having to worry about compatibility issues.

Designed and constructed to provide long-lasting USB capability, the adapter card is backed by StarTech.com's free lifetime technical support.

Certifikat, rapporter och kompatibilitet





Användning

- Add additional internal and external USB 2.0 ports to a desktop computer system
- Add an internal USB 2.0 header for use with internal/front-bay mounted USB peripherals
- Balance the number of available internal and external USB 2.0 ports on a computer system

Funktioner

- 4 external USB 2.0 ports and 3 internal USB 2.0 port/headers
- High Speed USB 2.0 compliant, with support for data transfer rates up to 480Mbps
- Backwards compatible with USB1.1/1.0 devices
- Up to 500mA of power per port
- Compliant with USB EHCI revision 0.95 and UHCI 1.1 specifications
- Compliant with PCI revision 2.2 specification
- Supports up to 127 USB devices (requires addition USB hubs)
- Plug-and-Play and Hot-Swap compatible

Hårdvara

Garantipolicy	2 Years
Portar	7
Gränssnitt	USB 2.0
Busstyp	PCI / PCI-X (5 / 3.3V)
Korttyp	Standardprofil
Industristandarder	EHCI 2.0
	OHCI 1.1

	Power Management 1.1
	PCI 2.2
Chipset-ID	VIA/VLI - VT6212
Prestanda	
Maximal dataöverföringshastighet	480 Mbps
Kontakt(er)	
Kontakttyp(er)	1 - PCI/PCI-X (universell 3,3 & 5 V, 32-bitars)
Interna portar	1 - USB 2.0 Type-A (4 stift, 480 Mbps)
	1 - IDC (10-stifts, moderkortskontakt)
Externa portar	4 - USB 2.0 Type-A (4 stift, 480 Mbps)
Mjukvara	
OS-kompatibilitet	Windows® 2000, XP, Vista, 7, 8, 8.1, 10, 11
	Windows Server® 2003, 2008 R2, 2012, 2016, 2019, 2022
	Mac OS X® 10.6 to 10.10
	Linux 3.5.x and up - LTS Versions only
Microsoft WHQL-certifierad	Ja
Särskilda anmärkningar/krav	
System- och kabelkrav	Unused PCI slot
Utseende	
Färg	Grön
Kabinettyp	Stål
Produktlängd	4.8 in [12.2 cm]
Produktbredd	4.7 in [12.0 cm]
Produkthöjd	0.8 in [2.0 cm]

	Produktvikt	2.6 oz [75.0 g]
Förpackning		
	Förpackningsantal	1
	Paketets längd	6.9 in [17.4 cm]
	Paketets bredd	5.6 in [14.3 cm]
	Paketets höjd	1.3 in [3.3 cm]
	Fraktvikt (förpackning)	5.2 oz [146.0 g]
Vad det är i lådan		
	Ingår i paketet	1 - PCI USB 2.0 Card
		1 - Driver CD
		1 - Instruction Manual
Warranty Information		
	Warranty	2 År

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.