

## 4 Port PCI Express PCIe Serial Combo Card - 2 x RS232 2 x RS422 / RS485

**Product ID:** PEX4S232485



The PEX4S232485 4 Port PCI Express PCIe Serial Combo Card - 2 x RS232 2 x RS422 / RS485 lets you add two RS232, and two RS422/485 serial ports to your PC through a PCI-Express expansion slot.

This PCI express serial card is a single card solution that is compatible with nearly any serial communication protocol, supporting RS-232, RS-422, RS-485 2-wire or RS-485 4-wire operating modes.

A flexible solution for adding serial ports to full-sized, or small form factor systems, the 4-port serial card includes both low and full profile brackets while the included breakout cable helps to avoid cluttered connections.

Backed by a StarTech.com lifetime warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

### Applications

- Monitor and control industrial machines on an assembly line or in a production environment
- POS retail applications in grocery stores, and any other retail store to control keyboards, cash drawers, receipt printers, card readers/card swipes, scales, and elevated displays on poles
- Bank teller workstations in either full profile or low profile versions to control their serial devices such as cash drawers, card readers / card swipes, printers, keypads / pinpads, pen pads
- Self-service automated machines and kiosks to control serial devices such as scales, touchscreens, magnetic card readers, bar code scanners, receipt printers, label printers

### Features

- RS232 data transfer rates up to 460 Kbps
- 256-byte deep FIFO per transmitter and receiver
- 4 port (2 x RS232, 2 x RS422/485) serial combo card
- Compliant with PCI-Express Specification 1.0a
- Supports PCI Power Management 1.1
- Standard and low-profile bracket included
- Supports 2-Wire / 4-Wire RS485 modes

---

#### Hardware

Warranty	Lifetime
Ports	4
Interface	Serial
Bus Type	PCI Express
Card Type	Standard Profile (LP bracket incl.)
Port Style	Dongle (Included)
Chipset ID	SystemBase - SB16C1052PCI

---

#### Performance

Serial Protocol	RS-232/422/485
Max Baud Rate	460.8 Kbps
Data Bits	5, 6, 7, 8
FIFO	256 Bytes
Flow Control	None, Xon/Xoff, RTS/CTS
Parity	None, Odd, Even, Space, Mark
Stop Bits	1, 1.5, 2
MTBF	85,288 hours
Supported Protocols	RS-232, RS-422, RS-485 2-wire / 4-wire

---



### Connector(s)

Connector Type(s)	PCI Express x1
External Ports	DB-9 (9 pin, D-Sub)

### Software

OS Compatibility	Windows 2000, XP, Vista, 7, 8, 8.1, 10 Windows Server 2003, 2008 R2, 2012, 2016, 2019
------------------	--

### Special Notes / Requirements

System and Cable Requirements	Available PCI Express slot
-------------------------------	----------------------------

### Environmental

Operating Temperature	0C to 100C (32F to 212F)
Storage Temperature	0C to 150C (32F to 302F)
Humidity	20~80% RH


### Physical Characteristics

Material	Steel
Product Length	5.3 in [13.4 cm]
Product Width	0.6 in [14 mm]
Product Height	2.7 in [69 mm]
Weight of Product	2.4 oz [67.4 g]

### Packaging Information

Package Length	8.3 in [21 cm]
Package Width	5.7 in [14.6 cm]
Package Height	1.6 in [41 mm]
Shipping (Package) Weight	13.8 oz [390 g]

### What's in the Box

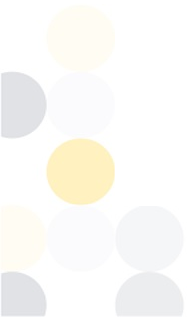

Included in Package	PCI Express Serial Combo Card
	Breakout Cable
	Low Profile Bracket
	Driver CD
	Instruction Manual

---

***\*Product appearance and specifications are subject to change without notice.***

