


4 Port PCI Express RS232 Serial Adapter Card with 16950 UART

Productcode: PEX4S950

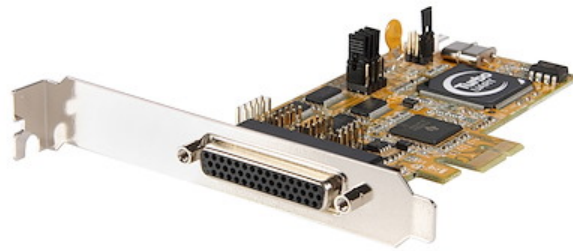

This PCI Express Serial Adapter card can be installed into any PCI Express slot on a computer, to provide four high performance 16C950 RS232 serial UART channels/ports - a convenient solution for connecting modern or legacy serial devices with support for data transfer rates of up to 460 Kbps.

The serial adapter card is easy to install, with support for Windows® 2000, XP, 2003 and Vista. Plus, the card features IRQ sharing and supports plug and play serial device connections, guaranteeing convenient, hassle-free installation.

The 4 Port PCI Express 16C950 Serial Card is backed by StarTech.com's lifetime warranty and FREE LIFETIME tech support.

Certificaties, rapporten en compatibiliteit

Toepassingen

- **Casino** (video lottery terminals, slot machines)
- **Consumer** (modems, PDAs, digital cameras, printers)
- **Environmental Control** (lighting, temperature, clocks)
- **Healthcare** (patient monitoring equipment, nurses' stations, modems)
- **Hospitality/Restaurant** (credit card/debit card reader, serial printers)
- **Hotel Front Desk** (serial printers, bar code scanners, keyboard, mouse, receipt printer,

credit/debit card reader)

- **ISDN Networking**
- **Manufacturing** (CNC machinery, process control equipment, bar code scanners, serial printers)
- **POS** (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)
- **Security** (UPS control, access key panels, video cameras, card readers, modems)

Eigenschappen

- UART's fully compatible with 16C550 type devices
- high performance 16C950 UART channel
- Fully Compliant with PCI Express Base Specifications, Revision 1.0a
- Supports 4 RS232 over one single PCI Express Slot
- Includes both Full and Low profile brackets for use with Slim and Micro systems

Hardware

Garantiebeleid	Lifetime
Poorten	4
Interface	Serieel
Bus type	PCI Express
Kaarttype	Standaard
Poorttype	Geïntegreerd op kaart
Chipsetcode	PLX/Oxford - OX16PCI954

Prestaties

Maximale overdrachtsnelheid	115.2 Kbps
Seriële protocol	RS-232
FIFO	128 Bytes

Connector(en)	Type connector(en)	PCI Express x1
	Externe poorten	DB-9 (9-polig, D-Sub)
<hr/>		
Software	Besturingssystemen	Windows® 8 (32/64bit), 7 (32/64), Vista(32/64), XP(32/64), ME, 98, 95
<hr/>		
Gebruiksomgeving	Bedrijfstemperatuur	0°C to 55°C (32°F to 131°F)
	Opslagtemperatuur	-40°C to 75°C (-40°F to 167°F)
	Vochtigheid	5~95% RH
<hr/>		
Fysieke eigenschappen	Kabellengte	11.0 in [28 cm]
	Lengte product	6.2 in [15.7 cm]
	Breedte product	0.8 in [20 mm]
	Hoogte product	4.7 in [12 cm]
	Gewicht product	10.9 oz [309 g]
<hr/>		
Verpakkingsinformatie	Package Length	9.1 in [23 cm]
	Package Width	6.5 in [16.5 cm]
	Package Height	1.7 in [42 mm]
	Verzendgewicht (verpakt)	14.1 oz [400 g]
<hr/>		
Wat wordt er meegeleverd	Meegeleverd	PCI EXPRESS CARD
		BREAKOUT CABLE
		DRIVER CD



INSTRUCTION MANUAL

* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.

