


4 Port PCI Express RS232 Serial Adapter Card with 16950 UART

Product ID: PEX4S950

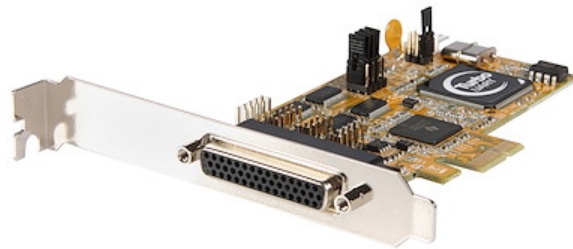

This PCI Express Serial Adapter card can be installed into any PCI Express slot on a computer, to provide four high performance 16C950 RS232 serial UART channels/ports - a convenient solution for connecting modern or legacy serial devices with support for data transfer rates of up to 460 Kbps.

The serial adapter card is easy to install, with support for Windows 2000, XP, 2003 and Vista. Plus, the card features IRQ sharing and supports plug and play serial device connections, guaranteeing convenient, hassle-free installation.

The 4 Port PCI Express 16C950 Serial Card is backed by StarTech.com's lifetime warranty and FREE LIFETIME tech support.

Certifications, Reports and Compatibility

Applications

- **Casino** (video lottery terminals, slot machines)
- **Consumer** (modems, PDAs, digital cameras, printers)
- **Environmental Control** (lighting, temperature, clocks)
- **Healthcare** (patient monitoring equipment, nurses' stations, modems)
- **Hospitality/Restaurant** (credit card/debit card reader, serial printers)
- **Hotel Front Desk** (serial printers, bar code scanners, keyboard, mouse, receipt printer, credit/debit card reader)
- **ISDN Networking**

- **Manufacturing** (CNC machinery, process control equipment, bar code scanners, serial printers)
- **POS** (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)
- **Security** (UPS control, access key panels, video cameras, card readers, modems)

Features

- UART's fully compatible with 16C550 type devices
- high performance 16C950 UART channel
- Fully Compliant with PCI Express Base Specifications, Revision 1.0a
- Supports 4 RS232 over one single PCI Express Slot
- Includes both Full and Low profile brackets for use with Slim and Micro systems

Hardware

Warranty	Lifetime
Ports	4
Interface	Serial
Bus Type	PCI Express
Card Type	Standard Profile
Port Style	Integrated on Card
Chipset ID	PLX/Oxford - OX16PCI954

Performance

Maximum Data Transfer Rate	115.2 Kbps
Serial Protocol	RS-232
FIFO	128 Bytes

Connector(s)

Connector Type(s)	PCI Express x1
External Ports	DB-9 (9 pin, D-Sub)

Software



OS Compatibility	Windows 8 (32/64bit), 7 (32/64), Vista(32/64), XP(32/64), ME, 98, 95
------------------	--

Environmental

Operating Temperature	0C to 55C (32F to 131F)
Storage Temperature	-40C to 75C (-40F to 167F)
Humidity	5~95% RH

Physical Characteristics

Cable Length	11.0 in [28 cm]
Product Length	6.2 in [15.7 cm]
Product Width	0.8 in [20 mm]
Product Height	4.7 in [12 cm]
Weight of Product	10.9 oz [309 g]

Packaging Information

Package Length	9.1 in [23 cm]
Package Width	6.5 in [16.5 cm]
Package Height	1.7 in [42 mm]
Shipping (Package) Weight	14.1 oz [400 g]

What's in the Box

Included in Package	PCI EXPRESS CARD
	BREAKOUT CABLE
	DRIVER CD
	INSTRUCTION MANUAL

**Product appearance and specifications are subject to change without notice.*

