


2 Port PCI Express PCIe SuperSpeed (5Gbps) USB 3.0 Controller Card w/ SATA Power

Produkt ID: PEXUSB3S23

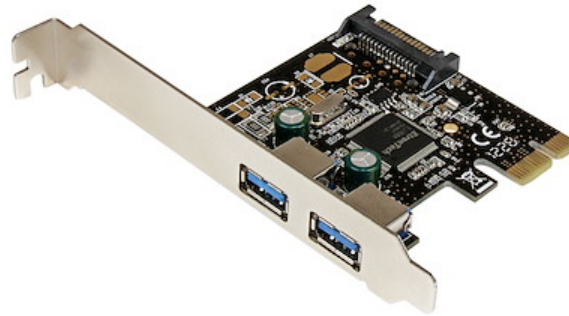

The PEXUSB3S23 2-Port PCI Express USB 3.2 Gen 1 Card lets you add two USB 3.2 Gen 1 ports to any PCI Express-enabled computer system. The USB card requires SATA power for functionality, and delivers 900mA of power per port to USB 3.2 Gen 1 bus-powered devices (500mA for USB 2.0) via your computer's SATA power connector.

The PCIe USB 3.2 Gen 1 adapter is compliant with USB 3.2 Gen 1 standards for data transfer speeds up to 5 Gbps, while still offering backward compatibility with existing USB 2.0 / 1.1 devices. For added versatility, the controller card is equipped with a standard profile bracket and includes a low-profile/half-height bracket for installation in small form-factor computers.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet



Användning

- Upgrade an older PCIe-based system with USB 3.2 Gen 1 connectivity to fully utilize USB 3.2 Gen 1 devices

- Expand the USB capabilities of your system with two additional external ports
- Connect additional external hard drives, CD/DVD drives, MP3 players, printers, scanners, webcams, game controllers, digital cameras, etc. to a computer system

Funktioner

- Provides two external USB 3.2 Gen 1 connections
- Supports data rates up to 5 Gbps
- SATA power connector (required) provides up to 900mA per USB port
- Compliant with PCI Express 2.0 specifications
- Fully compliant with USB 3.2 Gen 1 rev 1.0 and Intel xHCI rev 1.0 specifications
- Backward compatible with USB 2.0 and USB 1.0/1.1 devices
- Includes a Low Profile/half-height installation bracket

Hårdvara

Garantipolicy	2 Years
Portar	2
Gränssnitt	USB 3.2 Gen 1 (5 Gbps)
Busstyp	PCI Express
Korttyp	Standardprofil (inkl. LP-fäste)
Porttyp	Inbyggd på kort
Chipset-ID	Etron - EJ168A

Prestanda

Maximal kabellängd	9.8 ft [3 m]
Typ och hastighet	USB 3.0 - 5 Gbit/s
UASP-stöd	Nej

Kontakt(er)

Kontakttyp(er)	1 - PCI Express x1
----------------	--------------------

	Interna portar	1 - SATA-ström (15-stifts)
	Externa portar	2 - USB Type-A (9-stifts) USB 3.0 (5 Gbps)
Mjukvara	OS-kompatibilitet	Windows® XP, Vista, 7, 8, 8.1, 10, 11 Windows Server® 2003, 2008 R2, 2012, 2012 R2, 2016, 2019, 2022
Särskilda anmärkningar/krav	System- och kabelkrav	Available PCI Express slot Available 15-pin SATA power connector
Ström	Inspänning	12V DC
	Utpänning	12V DC
Miljö	Drifttemperatur	0°C to 60°C (32°F to 140°F)
	Förvaringstemperatur	0°C to 80°C (32°F to 176°F)
	Luftfuktighet	10~90% RH, Non-condensing
Utseende	Färg	Svart
	Kabinetttyp	Stål
	Produktlängd	3.1 in [8.0 cm]
	Produktbredd	0.8 in [2.1 cm]
	Produkthöjd	4.7 in [12.0 cm]
	Produktvikt	1.5 oz [43.0 g]
Förpackning	Förpackningsantal	1

Paketets längd	6.8 in [17.2 cm]
Paketets bredd	5.7 in [14.4 cm]
Paketets höjd	1.3 in [3.2 cm]
Fraktvikt (förpackning)	4.5 oz [128.0 g]

Vad det är i lådan

Ingår i paketet	1 - PCI Express USB 3.0 card
	1 - Low Profile Bracket
	1 - Driver CD
	1 - Instruction Manual

Warranty
Information

Warranty	2 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.