


4 Port PCI Express Low Profile High Speed USB Card - TAA

Produkt ID: PEXUSB4DP

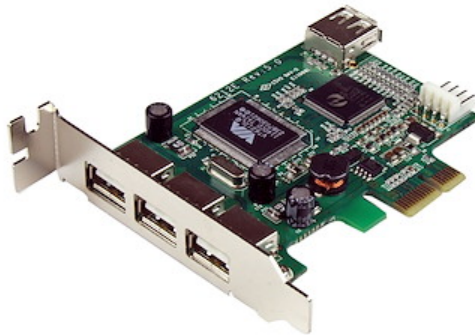

The PEXUSB4DP is a low profile 4 port USB card designed for versatility and performance.

Providing simple system expansion for added peripheral connections, this PCI Express USB card adds 3 external USB 2.0 slots and 1 internal USB 2.0 slot, with support for high speed USB 2.0 data transfer rates of up to 480 Mbps, and includes WHQL certified drivers and easy plug and play installation.

Capable of adapting to virtually any PC case form factor, the low profile USB card includes a standard profile bracket for installation in full form factor cases.

Certifikat, rapporter och kompatibilitet



Användning

- Add USB 2.0 connectivity to any PCIe based desktop, workstation or server
- Expand on a computers USB 2.0 capabilities with 4 additional ports for more USB device connections
- Add an internal USB port to connect internal or front-bay mounted USB devices
- Connect additional external hard drives, CD/DVD drives, MP3 players, printers, scanners, webcams, game controllers, digital cameras, etc. to a computer system

Funktioner

- 3 external and 1 internal USB 2.0 port
- High Speed USB 2.0 compliant, with transfer rates up to 480Mbps
- Backward compatible with USB 1.0/1.1 devices
- Provide up to 500mA of power per port with dedicated power input
- Plug-and-Play compatible
- Includes a full profile installation bracket

Hårdvara

Garantipolicy	2 Years
Portar	4
Gränssnitt	USB 2.0
Busstyp	PCI Express
Korttyp	Lågprofil (SP-fästen ingår)
Industristandarder	PCI Express One Lane 2.5Gb/s
Chipset-ID	VIA/VLI - VT6212
	ASMedia ASM1083

Prestanda

Typ och hastighet	USB 2.0 - 480 Mbit/s
-------------------	----------------------

Kontakt(er)

Kontakttyp(er)	1 - PCI Express x1
----------------	--------------------

	Interna portar	1 - SP4 (4-stifts, ström till liten enhet)
		1 - USB 2.0 Type-A (4 stift, 480 Mbps)
	Externa portar	3 - USB 2.0 Type-A (4 stift, 480 Mbps)
Mjukvara		
	OS-kompatibilitet	Windows® 2000, XP, Vista, 7, 8, 8.1, 10, 11
		Windows Server® 2003, 2008 R2, 2012, 2016, 2019, 2022
		Mac OS X® 10.6 to 10.10
		Linux 3.5.x and up - LTS Versions only
Särskilda anmärkningar/krav		
	System- och kabelkrav	PCI Express enabled computer with an available PCI Express x1 slot or higher
Miljö		
	Drifttemperatur	-0°C to 75°C (32°F to 167°F)
	Förvaringstemperatur	-40°C to 125°C (-40°F to 257°F)
	Luftfuktighet	80% RH
Utseende		
	Färg	Grön
	Kabinettyp	Stål
	Produktlängd	3.5 in [9.0 cm]
	Produktbredd	3.1 in [8.0 cm]
	Produkthöjd	0.8 in [2.0 cm]
	Produktvikt	1.6 oz [46.0 g]
Förpackning		
	Förpackningsantal	1
	Paketets längd	6.7 in [17.0 cm]
	Paketets bredd	5.7 in [14.4 cm]

Paketets höjd 1.3 in [3.2 cm]

Fraktvikt (förpackning) 4.2 oz [120.0 g]

Vad det är i lådan

Ingår i paketet	1 - PCI Express USB 2.0 Card
	1 - Full Profile Bracket
	1 - Driver CD
	1 - Instruction Manual

Warranty
Information

Warranty	2 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.