


8 ft Computer Power Cord - NEMA 5-15P to IEC 320 C19

Product ID: PXT515C198

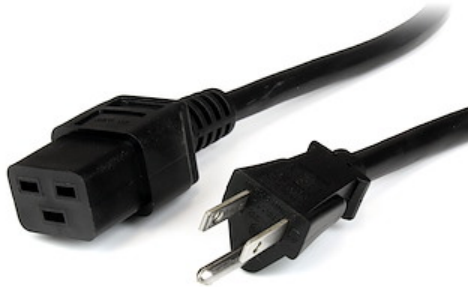

The PXT515C198 Computer Power Cord (8ft) has 1 NEMA 5-15P connector and 1 IEC 320 C19 connector - a durable, heavy duty power cable that is designed to work with your PC, or can be used in a server room for reliable power delivery.

Like all cables, this computer power cable is backed by StarTech.com's lifetime warranty.

Certifications, Reports and Compatibility



Applications

- Can be used in a server room to provide a reliable power connection for server applications

Features

- 15A/125V

Hardware

Warranty	Lifetime
Number of Conductors	3

	Cable Jacket Material	PVC - Polyvinyl Chloride
	Cable Type	SJT
Connector(s)		
	Connector A	1 - NEMA 5-15 Power (North America)
	Connector B	1 - IEC 60320 C19 Power
Physical Characteristics		
	Color	Black
	Wire Gauge	14 AWG
	Cable Length	8.0 ft [2.4 m]
	Product Length	8.0 ft [2.4 m]
	Product Width	1.3 in [3.4 cm]
	Product Height	0.9 in [2.4 cm]
	Weight of Product	14.8 oz [420.0 g]
Packaging Information		
	Package Quantity	1
	Package Length	11.4 in [29.0 cm]
	Package Width	5.5 in [14.0 cm]
	Package Height	1.5 in [3.8 cm]
	Shipping (Package) Weight	15.1 oz [427.0 g]
What's in the Box		
	Included in Package	1 - 8 ft Computer Power Cord - NEMA 5-15P to IEC 320 C19
Warranty Information		
	Warranty	Lifetime

**Product appearance and specifications are subject to change without notice.*