


Computer Power Cord - C19 to C20, 14 AWG, 6 ft

Product ID: PXTC19C20146

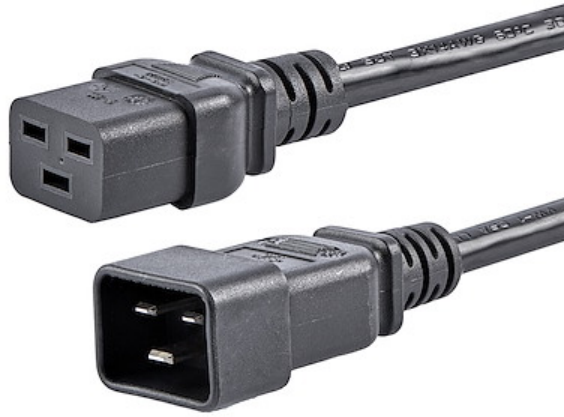

This C19-to-C20 power cord features 14 AWG wire that's suitable for high-power connections, making it perfect for server applications and connecting to a Power Distribution Unit (PDU).

Plus, you can use the cable to extend the reach of your existing power cord by 6 feet, which gives you the extra distance you need to place your devices according to your server room configuration.

Expertly designed and constructed of high-quality materials, the StarTech.com PXTC19C20146 power cord is backed by a lifetime warranty.

Certifications, Reports and Compatibility

Applications

- Connect your server to a PDU
- Extend the connection between your server and PDU by up to 6 feet

Features

- Rated to carry 250V at 15A
 - 14 AWG wire
 - UL, RoHS compliant
-

Hardware

Warranty	Lifetime
Number of Conductors	3
Cable Jacket Material	PVC - Polyvinyl Chloride
Cable Type	SJT

Connector(s)

Connector A	IEC 60320 C19 Power
Connector B	IEC 60320 C20 Power

Special Notes / Requirements

Note	UL Listed
------	-----------

Power

Input Voltage	250 AC
Input Current	15 A

Physical Characteristics

Color	Black
Wire Gauge	14 AWG
Cable Length	6.0 ft [1.8 m]
Product Length	6.0 ft [1.8 m]
Product Width	0.0 in [0.0 mm]
Product Height	0.0 in [0.0 mm]
Weight of Product	12.6 oz [356.0 g]

Packaging Information

Package Quantity	1
Package Length	11.4 in [29.0 cm]
Package Width	5.7 in [14.5 cm]
Package Height	1.6 in [40.0 mm]



Shipping (Package) Weight	12.8 oz [363.0 g]
------------------------------	-------------------

**What's in the
Box**

Included in Package	6 ft 14 AWG Computer Power Cord - C19 to C20
---------------------	--

****Product appearance and specifications are subject to change without notice.***

